




What can we help you find?

- [Products](#)
- [Industries](#)
- [Resources](#)
- [About TE](#)
- [My Account](#)
- [Innovation](#)
- [Support Center](#)

202W312-25-0 Product Details

- [Share](#)
- [Print](#)
- [Email](#)

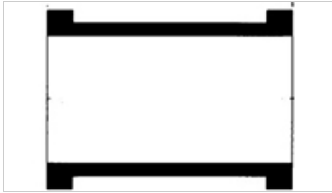

Active

Molded Parts

202W312-25-0

202W312-25-0

TE Internal Number: 861780-000

Product Highlights [View All](#)

- SAE AS81765/1 Type I
- Molded Part Type = Bobbins
- Molded Part Shape = Straight
- Operating Temperature = -75 - 150 °C
- 180°

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

- [Documents](#)
- [Features](#)
- [Compliance](#)

Please Note:

Use the Product Drawing for all design activity

Product Type Features

Molded Part Type	Bobbins
Molded Part Shape	Straight
Angle	180°
Adhesive Description	Adhesive Purchased Separately
Size	12
Family Name	202W3
Color	Black

Mechanical Attachment

Adhesive Pre-Coating	Without
----------------------	---------

Dimensions

Expanded ID, Min. (mm [in])	40.00 [1.575]
Recovered ID, Max. (mm [in])	12.80 [0.500]

Body Features

Wall Thickness - Full Recovery (Nominal) (mm [in])	2.00 [0.079]
--	--------------

Configuration Features

Material Code	25
---------------	----

Industry Standards

Government/Industry Qualification	No
Approved Standards	SAE AS81765/1 Type I
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

Environmental

Operating Temperature (°C)	-75 - +150
----------------------------	------------

Operation/Application

Application	General Purpose
-------------	-----------------

Purchasing Information

Adhesive Code	S1017, S1048, S1125
---------------	---------------------

Material	Fluid Resistant Modified Polyester	Other	
Housing Features		Brand	Raychem
Material Systems Code	25		
Max. Inside Diameter of Part (mm [in])	12.70 [0.500]		

Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

