


177469-000 Product Details

 [Live Product Chat](#)

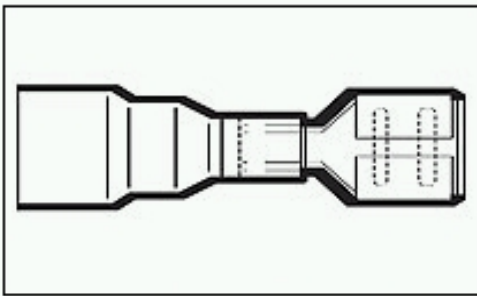

177469-000

TE Part Number: 177469-000

 [Active](#)

 [Add to Part List](#)

Quick Disconnect Receptacles - Insulated

 [Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Proprietary Name = DuraSeal
- Receptacle Style = Straight
- Wire Range = 1.50-2.50² [15.5-13.5] mm [AWG]
- Tab Fit = 6.35 x 0.81 mm
- Insulation Diameter = 4.57 [.180] Max. mm [in]

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [Duraseal Push-on Receptacle](#) (PDF, English)

Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Schematic](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Proprietary Name](#) = DuraSeal
- [Receptacle Style](#) = Straight
- [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- [Insulation Diameter \(mm \[in\]\)](#) = 4.57 [.180] Max.
- [Insertion Force](#) = Normal
- [Material](#) = Brass
- [Finish](#) = Tin
- [Dimple Type](#) = No dimple without wire stop
- Insulation Support = Insulation Support
- Color = Blue
- Insulation Material = Heat-Shrinkable Nylon

Body Related Features:

- [Fully Insulated](#) = No
- [Wire Range \(mm \[AWG\]\)](#) = 1.50-2.50² [15.5-13.5]
- Wire Range (CMA) = 2,050 – 5,180

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Temperature Range (°C) = 125

Packaging Related Features:

- [Packaging Method](#) = Bulk

Other:

- Brand = Raychem

 [Provide Website Feedback](#) | [Need Help?](#)