


82A0112-28-9 Product Details

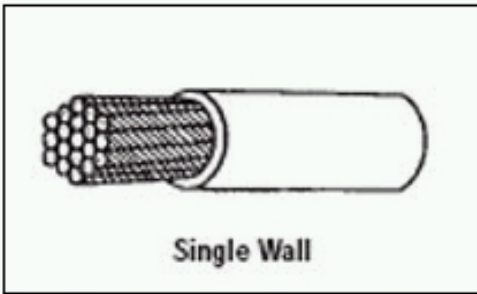

82A0112-28-9

TE Part Number: 244922-000

✓ [Active](#)

[Add to Part List](#)

Spec 80 (FlexLine) Wire

✓ [Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

Product Highlights:

- Stranding = High Strand Count Conductor
- Wall Type = Single
- Cable Style = Primary
- Voltage = 600 VAC
- Class of Wire = Equipment

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [WIRE, RADIATION-CROSSLINKED, MODIFIED FLEXIBLE ETFE-...](#) (PDF, English)

Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Cable Style = Primary
- Number of Conductors = 1

Electrical Characteristics:

- Stranding = High Strand Count Conductor
- Voltage (VAC) = 600

Body Related Features:

- Wall Type = Single
- Conductor Type = Silver-Plated Copper
- Wire Size (AWG/CM) = 28 AWG
- Wire Color = White

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Class of Wire = Equipment

Other:

- Brand = Raychem