


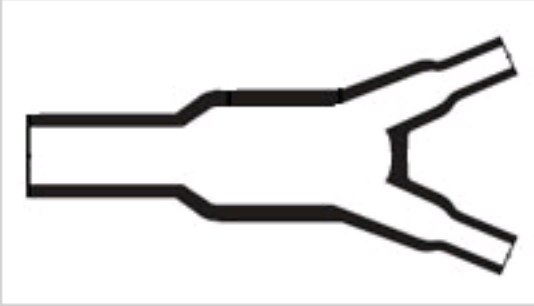

382A012-100/86-0 Product Details

[Share](#) | [Print](#) | [Email](#)


Active

Molded Parts

382A012-100/86-0

382A012-100/86-0

TE Internal Number: 604791-000

Product Highlights [View All](#)

- VG95343 Parts 29 and 30
- Molded Part Type = Transition
- Molded Part Shape = Y
- Molded Part Lip = Without Lip
- Operating Temperature = -30 - 80 °C

[Pricing & Availability](#)

[Request Sample](#)

[Add to My Part List](#)

[Buy Product through Distributor](#)

Feedback

Documents

Features

Compliance

Please Note:
Use the Product Drawing for all design activity

Product Type Features	
Molded Part Type	Transition
Molded Part Shape	Y
Molded Part Lip	Without Lip
Angle	22.5°
Adhesive Description	High Performance Pre-Coat Adhesive
Size	12
Family Name	382A0
Color	Black

Mechanical Attachment	
Adhesive Pre-Coating	With

Dimensions	
Cable Diameter Range (mm [in])	6.10 - 13.20 [0.240 - 0.520]
1st Branch/Leg Range (mm [in])	3.30 - 6.60 [0.130 - 0.260]
2nd Branch/Leg Range (mm [in])	3.30 - 6.60 [0.130 - 0.260]
Expanded ID, Min. (mm [in])	13.20 [0.520]
Recovered ID, Max. (mm [in])	6.10 [0.240]

Body Features	
Transition Type	Y
Material	Fluid Resistant Modified Elastomer

Housing Features	
Material Systems Code	100
Max. Inside Diameter of Part (mm [in])	6.10 [0.240]

Configuration Features	
Material Code	100
Number of Branches/Legs	2

Industry Standards	
Government/Industry Qualification	No
Approved Standards	VG95343 Parts 29 and 30
RoHS/ELV Compliance	RoHS compliant, ELV compliant
Lead Free Solder Processes	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant

Environmental	
Operating Temperature (°C)	-30 - +80

Operation/Application	
Application	General Purpose

Purchasing Information	
Adhesive Code	86

Other	
Brand	Raychem

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed

