




HARNESSING

SOLDERSLEEVE SHIELD TERMINATORS

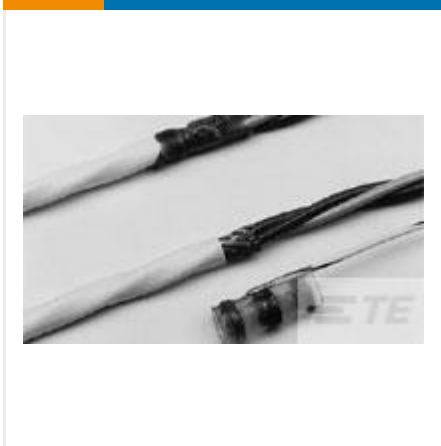

✓ Active

TE CONNECTIVITY (TE)

CWT-6-W122-5

Raychem | Cat 6 , Terminator

CWT-6-W122-5

TE Internal Number: 416947-000

Alias ID: 1-1193142-6

Not EU RoHS Compliant

Not EU ELV Compliant

Product Type Shield Terminator

Operating Temperature (Max) (°C) 125

Expanded Inside Diameter (Min) 6 mm [.236 in]

Pre-Installed Lead Yes

Resistance Properties Splash Protection



PRODUCT DRAWING

English

DOCUMENTATION

Product Drawings

SolderSleeve Terminator With Pre-Installed Lead

PDF

English

Product Specifications

Product Specification

SolderSleeve Insulated Electrical Termination Devices

PDF

English

SolderSleeve One-Step Wire And Cable Terminators Installation Procedures For CWT Products

PDF

English

Product Environmental Compliance

REACH Substance Communication Document

RSCD_Cadmium

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type Shield Terminator

Temperature Indicator Yes

Temperature Indicator Type Thermochromic

Configuration Features

Pre-Installed Lead Yes

Pre-Installed Lead Type XL Polyethylene

Body Features

Shield Outside Diameter (Min) 3.3 mm [.13 in]

Lead Stranding Stranded (W1)

Lead Color White

Lead Plating Material Tin

Dimensions

Expanded Inside Diameter (Min) 6 mm [.236 in]

Overall Length 32 mm [1.26 in]

Pre-Installed Lead Wire Size (mm²) .38

Jacket Outside Diameter 6 mm [.236 in]

Usage Conditions

Operating Temperature (Max) (°C) 125

Resistance Properties Splash Protection

Wire Temperature (Max) (°C) 105

Industry Standards

Government Qualified No

Statement of Compliance

Statement of Compliance

PDF