


214A011-25/225-0 Product Details

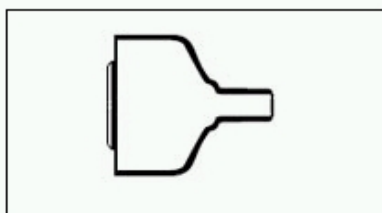

214A011-25/225-0

TE Internal Number: 714998-000

 [Active](#)

Molded Parts

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

Product Highlights:

- Molded Part Type = D Subminiature Boot
- Family Name = 214A0
- Straight
- General Purpose Application, Military Application
- 25 Material Systems Code

[View all Features](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

 [Add to My Part List](#) |
  [Request Sample](#) |
  [Find Similar Products](#) |
  [Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [Boot, Rectangular, Subminiature, Straight \(1\)](#) (PDF, English)
- [Boot, Rectangular, Subminiature, Straight \(2\)](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Additional Information:

- [Product Line Information](#)

Additional Product Images:

- [Product Photo](#)
- [Specifications](#)

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Molded Part Type = D Subminiature Boot
- Angle = Straight
- Size = 11
- Material = Fluid Resistant Modified Elastomer

Body Features:

- Cable Diameter Range (mm [in]) = 4.10 - 7.90 [0.161 - 0.311]
- Connector Length (mm [in]) = 20.00 - 20.30 [0.787 - 0.799]
- Connector Width (mm [in]) = 10.70 [0.421]

Contact Features:

- [Family Name](#) = 214A0

Housing Features:

- [Material Systems Code](#) = 25
- Adhesive Pre-Coating = With
- Adhesive Description = Unicure Pre-Coated Epoxy Adhesive

Configuration Features:

- Material Code = 25
- Adhesive Code = 225

Industry Standards:

- Government/Industry Qualification = No
- Approved Standards = MIS-34867
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Environmental:

- Operating Temperature (°C) = -75 - +150

Operation/Application:

- Application = General Purpose, Military

Other:

- Brand = Raychem

Corporate Information

[Who We Are](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)

Quick Links

[Check Distributor Inventory](#)
[Cross Reference](#)
[Find Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Search Knowledge Base](#)
[Manage your Account](#)

Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address 