


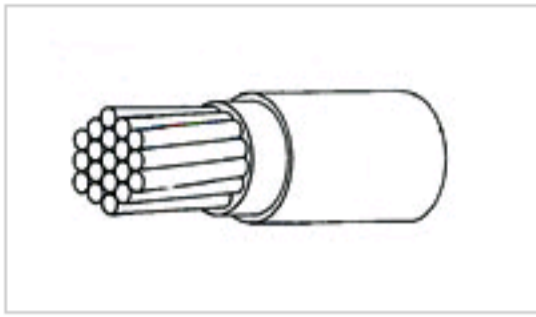

44A0111-20-0-MX Product Details

[Share](#) | [Print](#) | [Email](#)


✔ Active

Spec 44, Spec 55 and Spec RCW Wire and Cable

44A0111-20-0

44A0111-20-0-MX ✔

TE Internal Number: 282020-018

Product Highlights [View All](#)

- Cable Type = Spec 44
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 20 AWG
- Voltage Rating = 600 VAC

[Pricing & Availability](#) ➤

[Request Sample](#) ➤

[Add to My Part List](#) +

[Buy Product through Distributor](#) ➤

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

Please Note:

Use the Product Drawing for all design activity

| Product Type Features | | Industry Standards | |
|------------------------------------|-------------------|---|---|
| Cable Type [?] | Spec 44 | Government/Industry Qualification | No |
| Cable Style [?] | Primary | RoHS/ELV Compliance [?] | RoHS compliant, ELV compliant |
| Electrical Characteristics | | Lead Free Solder Processes [?] | Not relevant for lead free process |
| Voltage Rating (VAC) | 600 | RoHS/ELV Compliance History | Always was RoHS compliant |
| Dimensions | | Conditions for Usage | |
| Conductor Outer Diameter (mm [in]) | 1.01 [0.040] | Temperature Range (°C) | -65 - +150 |
| Body Features | | Wire Size - Details | 20 AWG 0.62 mm ² , 0.00095 in ² , 19 x 32 AWG |
| Wire Size (AWG/CM) | 20 AWG | Operation/Application | |
| Conductor Type | Tin-Coated Copper | Application | General Purpose - Light Weight |
| Wire Color | Black | Packaging Features | |
| Nominal Outside Diameter (mm [in]) | 1.40 [0.055] | Wire Source | United States |
| Wire Diameter (mm [in]) | 1.40 [0.055] | Other | |
| Configuration Features | | Brand | Raychem |
| Number of Conductors | 1 | Node Classification | Hook Up Wire |

Related Products

Not quite the product you're looking for?
[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)