


## CWT-1504 Product Details

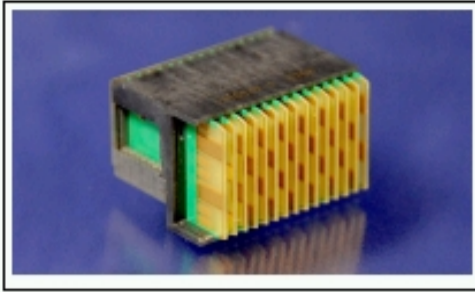

### CWT-1504

TE Part Number: 514649-000

✓ Active

➤ [Add to Part List](#)

### SolderPak Wire Terminators

[Not EU RoHS or ELV Compliant](#)

#### Product Highlights:

- Terminal Type = Pin, Post, Tab
- Operating Temperature (Max.) = 125 °C
- Wire Size to Pin/Post = .61 - .95 mm<sup>2</sup>
- Wire Size to Tab = .24 - .95 mm<sup>2</sup>
- Pin/Post Width = 1.14 - 1.52 mm

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

## Documentation & Additional Information

### Product Drawings:

- [SolderSleeve One Step Wire Terminator Low Temperature](#) (PDF, English)

### Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

### Product Specifications:

- None Available

### Application Specifications:

- None Available

### Instruction Sheets:

- None Available

### CAD Files:

- None Available

### Related Products:

- [Tooling](#)

[List all Documents](#)

## Product Features (Please use the Product Drawing for all design activity)

### Product Type Features:

- [Terminal Type](#) = Pin, Post, Tab
- Tab Width (mm [in]) = 2.54 - 3.8 [0.1 - 0.15]
- Connection Type = Solder

### Housing Related Features:

- Wire Size to Pin/Post (mm<sup>2</sup> [AWG]) = 0.61 - 0.95 [18 - 20]
- Wire Size to Tab (mm<sup>2</sup> [AWG]) = 0.24 - 0.95 [18 - 24]
- Pin/Post Width (mm [in]) = 1.14 - 1.52 [0.045 - 0.060]
- Tape Carrier = Without

### Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

### Conditions for Usage:

- [Operating Temperature \(Max.\) \(°C\)](#) = 125

### Operation/Application:

- Application Type = Wire termination to pin/post/tab

### Other:

- Brand = Raychem