


## B-106-4631 Product Details

 [Live Product Chat](#)

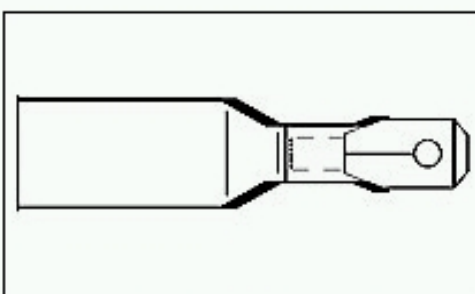

### B-106-4631

TE Part Number: 514711-000

 [Active](#)

 [Add to Part List](#)

### Quick Disconnect Tabs, Tab Adapters & Tab Caps

 [Always EU RoHS/ELV Compliant](#) ([Statement of Compliance](#))

#### Product Highlights:

- Tab
- Tab Type = Wire Crimp
- Insulated
- Tab Fit = 6.35 x 0.81 mm
- Brass Material

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- [Duraseal Blade Terminal](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Additional Product Images:

- [Schematic](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Tab
- [Insulation](#) = Yes
- [Tab Fit \(mm \[in\]\)](#) = 6.35 x 0.81 [.250 x .032]
- [Material](#) = Brass
- [Insulation Diameter \(mm \[in\]\)](#) = 4.00 [.157] Max.
- [Finish](#) = Tin
- [Wire/Cable Type](#) = Regular Wire
- [Mount Angle](#) = Straight
- Insulation Support = Without
- Color = Red
- Proprietary Name = DuraSeal

#### Body Related Features:

- [Tab Type](#) = Wire Crimp
- [Wire Range \(mm \[AWG\]\)](#) = 0.30-0.90<sup>2</sup> [22-18]
- Stud Hole = Without

#### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Conditions for Usage:

- Temperature Range (°C) = 125

#### Packaging Related Features:

- [Packaging Method](#) = Loose Piece

#### Other:

- Brand = Raychem

 [Provide Website Feedback](#) | [Need Help?](#)