


## 462W013-25-0 Product Details

Share Print Email

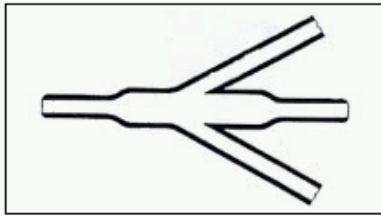

462W013-25-0

TE Internal Number: 879057-000

Active

### Molded Parts

Always EU RoHS/ELV Compliant (Statement of Compliance)

#### Product Highlights:

- Molded Part Type = Transition
- Family Name = 462W0
- Transition Type = One to Three Cables
- 3 Branches/Legs
- General Purpose Application, Military Application

[View all Features](#)

### Quick Links

- Check Pricing & Availability
- Search for Tooling
- Product Feature Selector
- Contact Us About This Product

[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [Customer Drawing](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Molded Part Type = Transition
- Size = 13
- Material = Fluid Resistant Modified Elastomer

#### Body Features:

- Transition Type = One to Three Cables
- Number of Branches/Legs = 3
- 1st Branch/Leg Range (mm [in]) = 4.80 - 10.00 [0.189 - 0.394]
- 2nd Branch/Leg Range (mm [in]) = 4.80 - 10.00 [0.189 - 0.394]
- 3rd Branch/Leg Range (mm [in]) = 4.80 - 10.00 [0.189 - 0.394]

#### Contact Features:

- Family Name = 462W0

#### Housing Features:

- [Material Systems Code](#) = 25
- Adhesive Pre-Coating = Without
- Adhesive Description = Adhesive Purchased Separately.
- Max. Inside Diameter of Part (mm [in]) = 4.80 - 10.00 [0.189 - 0.394]

#### Configuration Features:

- Material Code = 25
- Adhesive Code = S1125

#### Industry Standards:

- Government/Industry Qualification = No
- Approved Standards = DEF Std 59-97 Issue 3 Type DE, MIS-34867, VG95343 Parts 6, 7, 8, & 9
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Environmental:

- Operating Temperature (°C) = -75 - +150

#### Operation/Application:

- Application = General Purpose, Military

#### Other:

- Brand = Raychem
- Comment = Contact Raychem for additional adhesive and/or cut off boot length information

### Corporate Information

[Who We Are](#)  
[Investors](#)  
[News Room](#)  
[Supplier Portal](#)  
[Careers](#)

### Quick Links

[Check Distributor Inventory](#)  
[Cross Reference](#)  
[Find Documents & Drawings](#)  
[Product Compliance Support Center](#)  
[Site Map](#)

### Customer Support

[Email or Chat With Us](#)  
[Find a Phone Number](#)  
[Search Knowledge Base](#)  
[Manage your Account](#)

### Keep Me Informed

Receive TE News, Events & Technology Updates

Enter your email address

