




[+ TERMINALS & SPLICES](#)

[SPLICES](#)

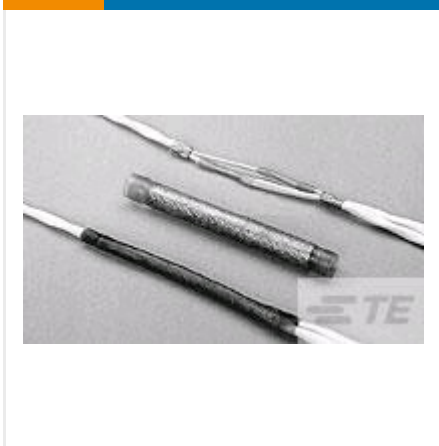

✓ Active

TE CONNECTIVITY (TE)
D-150-0180

Raychem

594677-000

TE Internal Number: 594677-000

Alias ID: 3-1194701-4

Not EU RoHS Compliant

Not EU ELV Compliant

Product Type Splice

Terminal & Splice Style Splice

Splice Type SolderShield

Wire/Cable Type Multi-Conductor

Operating Temperature Range (°C) 150

[↓ PRODUCT DRAWING](#)
English

DOCUMENTATION

Product Drawings

[1 To 1 Splices-Crimp SolderShield Splice Kit, Shielded Cable](#)

PDF

English

Catalog Pages/Data Sheets

[1654025_Sec8_D-150](#)

PDF

English

Product Specifications

Product Specification

[Installation Procedure For TE Connectivity Shielded Cable Splice Kits With Mini-Seal Crimp Primary Splices](#)

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type Splice
Splice Type SolderShield
Wire/Cable Type Multi-Conductor

Configuration Features

Number of Conductors Four-conductor cable, Three-conductor cable

Body Features

Plating Material Tin/Silver

Contact Features

Terminal & Splice Style Splice

Usage Conditions

Operating Temperature Range (°C) 150

PRODUCT COMPLIANCE



Statement of Compliance

Statement of Compliance

PDF
