


CWT-1501 Product Details

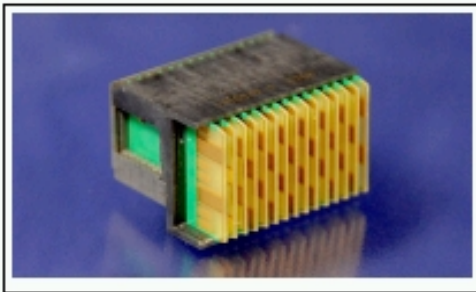

CWT-1501

TE Part Number: 667353-000

✓ [Active](#)

[Add to Part List](#)

SolderPak Wire Terminators

[Not EU RoHS or ELV Compliant](#)

Product Highlights:

- Terminal Type = Pin, Post, Tab
- Operating Temperature (Max.) = 125 °C
- Wire Size to Pin/Post = .24 mm², .24 - .61 mm²
- Wire Size to Tab = .24 - .61 mm²
- Pin/Post Width = .63 mm, .63 - .89 mm

[View all Features](#) | [Find Similar Products](#)

Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

NEW!

Documentation & Additional Information

Product Drawings:

- [SolderSleeve One Step Wire Terminator Low Temperature](#) (PDF, English)

Catalog Pages/Data Sheets:

- [Wire and Cable, Harnessing and Protection Products](#) (PDF, English)

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Terminal Type](#) = Pin, Post, Tab
- Tab Width (mm [in]) = 1.52 [0.06]
- Connection Type = Solder
- Comment = Fits wire size up to 1.52 [.060]

Housing Related Features:

- Wire Size to Pin/Post (mm² [AWG]) = 0.24 [24], 0.24 - 0.61 [20 - 24]
- Wire Size to Tab (mm² [AWG]) = 0.24 - 0.61 [20 - 24]
- Pin/Post Width (mm [in]) = 0.63 [0.025], 0.63 - 0.89 [0.025 - 0.035]
- Tape Carrier = Without

Industry Standards:

- [RoHS/ELV Compliance](#) = Not ELV/RoHS compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process

Conditions for Usage:

- [Operating Temperature \(Max.\) \(°C\)](#) = 125

Operation/Application:

- Application Type = Wire termination to pin/post/tab

Other:

- Brand = Raychem

[Provide Website Feedback](#) | [Need Help?](#)