


## D-609-03 Product Details

 [Live Product Chat](#)

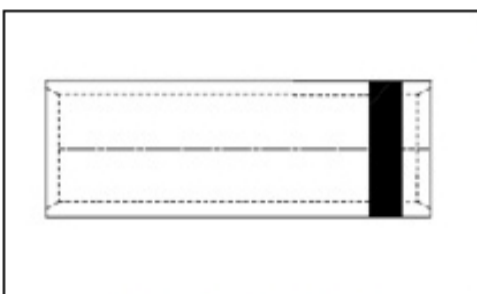

### D-609-03

TE Part Number: 680104-000

 [Active](#)

 [Add to Part List](#)

### Splices - Closed Barrel

 [Always EU RoHS/ELV Compliant \(Statement of Compliance\)](#)

#### Product Highlights:

- Splice
- Not Sealed
- Splice Type = Butt
- Butt Splice Type = Standard
- Body Style = DuraSeal

[View all Features](#) | [Find Similar Products](#)

### Quick Links

- ▶ [Check Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)
- ▶ [Request Samples](#)

**NEW!**

### Documentation & Additional Information

#### Product Drawings:

- [Crimp Splicer, Stub](#) (PDF, English)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- [Product Type](#) = Splice
- [Sealed](#) = No
- [Splice Type](#) = Butt
- Body Style = DuraSeal
- [Insulation](#) = No
- Material = Copper Alloy
- [Finish](#) = Tin
- Color = None
- Connection Type = Crimp
- Comment = Not all wire combinations falling within the CMA range can be accommodated within the splice barrel.

#### Mechanical Attachment:

- Inside Diameter (mm [in]) = 1.27 [0.050]
- Ring Color = Red

#### Body Related Features:

- [Butt Splice Type](#) = Standard
- [Wire Range \(CMA\)](#) = 300 - 1,510

#### Industry Standards:

- Government/Industry Qualification = No
- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Operation/Application:

- Application Type = Wire to wire splicing

#### Packaging Related Features:

- [Packaging Method](#) = Loose Piece

#### Other:

- Brand = Raychem