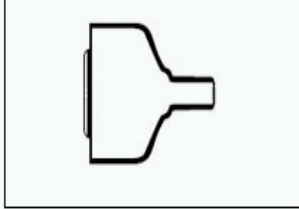


## 214A021-4-0 Product Details

[Share](#) | [Print](#) | [Email](#)


214A021-4-0

### Molded Parts

Always EU RoHS/ELV Compliant (Statement of Compliance)

#### Product Highlights:

- Molded Part Type = D Subminiature Boot
- Family Name = 214A0
- Straight
- General Purpose Application
- 10 Material Systems Code

[View all Features](#)

### Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

TE Internal Number: 808226-000

Active

[Add to My Part List](#)
[Request Sample](#)
[Find Similar Products](#)
[Buy Product](#)

### Documentation & Additional Information

#### Product Drawings:

- [Boot, Rectangular, Subminiature, Straight \(PDF, English\)](#)

#### Catalog Pages/Data Sheets:

- None Available

#### Product Specifications:

- None Available

#### Application Specifications:

- None Available

#### Instruction Sheets:

- None Available

#### CAD Files:

- None Available

#### Additional Information:

- [Product Line Information](#)

#### Related Products:

- [Tooling](#)

[List all Documents](#)

Feedback

### Product Features (Please use the Product Drawing for all design activity)

#### Product Type Features:

- Molded Part Type = D Subminiature Boot
- Family Name = 214A0
- Angle = Straight
- Adhesive Description = Adhesive Purchased Separately.
- Size = 21

#### Mechanical Attachment:

- Adhesive Pre-Coating = Without

#### Dimensions:

- Cable Diameter Range (mm [in]) = 5.30 - 10.20 [0.209 - 0.402]
- Connector Length (mm [in]) = 28.00 - 28.20 [1.102 - 1.110]
- Connector Width (mm [in]) = 10.70 [0.421]

#### Body Features:

- Material = Polyolefin Flexible Modified

#### Housing Features:

- Material Systems Code = 10

#### Configuration Features:

- Material Code = 4

#### Industry Standards:

- Government/Industry Qualification = No
- Approved Standards = DEF Std 59-97 Issue 3 Type DA, MIL-I-81765/1 Class I, UL224 E85831
- RoHS/ELV Compliance = RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

#### Environmental:

- Operating Temperature (°C) = -55 - +135

#### Operation/Application:

- Application = General Purpose

#### Purchasing Information:

- Adhesive Code = S1125

#### Other:

- Brand = Raychem
- Comment = Contact Raychem for additional adhesive and/or cut off boot length information

### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [AODA Accessibility Policy](#)
- [AODA Multi-Year Accessibility Plan](#)

### Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

### Keep Me Informed

