


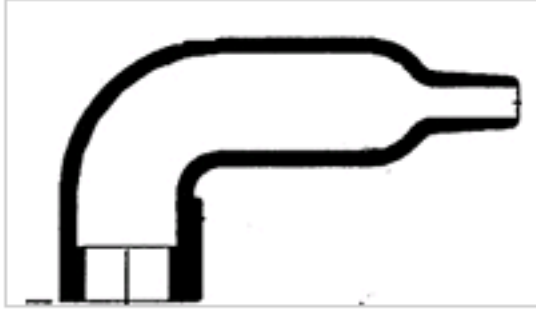

# 223W301-25-0 Product Details

[+ Share](#) | [Print](#) | [Email](#)


✔ Active

## Molded Parts

223W301-25-0

**223W301-25-0** ✔

TE Internal Number: F70695-000

### Product Highlights [View All](#)

- VG95343 Parts 6,7,8 and 9
- Molded Part Type = Molded Boot
- Molded Part Shape = 90°
- Molded Part Lip = With Lip
- Operating Temperature = -75 - 150 °C

[Pricing & Availability](#) ➔

[Request Sample](#) ➔

[Add to My Part List](#) +

[Buy Product through Distributor](#) ➔

Feedback

[Documents](#) | [Features](#) | [Compliance](#)

### Please Note:

Use the Product Drawing for all design activity

Product Type Features	
Molded Part Type <span style="font-size: small;">?</span>	Molded Boot
Molded Part Shape	90°
Molded Part Lip	With Lip
Angle	90°
Adhesive Description	Adhesive Purchased Separately
Size	01
Family Name	223W3
Color	Black
Mechanical Attachment	
Adhesive Pre-Coating	Without
Dimensions	
Cable Diameter Range (mm [in])	5.80 - 10.00 [0.230 - 0.390]
Expanded ID, Min. (mm [in])	5.80 [0.230]
Recovered ID, Max. (mm [in])	9.90 [0.390]
Body Features	
Material	Fluid Resistant Modified Elastomer
Housing Features	
Material Systems Code <span style="font-size: small;">?</span>	25
Max. Inside Diameter of Part (mm [in])	5.90 [0.230]

Configuration Features	
Material Code	25
Industry Standards	
Government/Industry Qualification	No
Approved Standards	VG95343 Parts 6,7,8 and 9
RoHS/ELV Compliance <span style="font-size: small;">?</span>	RoHS compliant, ELV compliant
Lead Free Solder Processes <span style="font-size: small;">?</span>	Not relevant for lead free process
RoHS/ELV Compliance History	Always was RoHS compliant
Environmental	
Operating Temperature (°C)	-75 - +150
Operation/Application	
Application	General Purpose
Purchasing Information	
Adhesive Code	S1017, S1048, S1125
Other	
Brand	Raychem

### Related Products

Not quite the product you're looking for?

[Find Similar Products](#)

[View Part in Product Feature Selector](#)

[Check for Tooling](#)

### Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [Global Accessibility Statement](#)

### Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

### Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

### Keep Me Informed

