




HARNESSING

SHIELDED CONTACTS

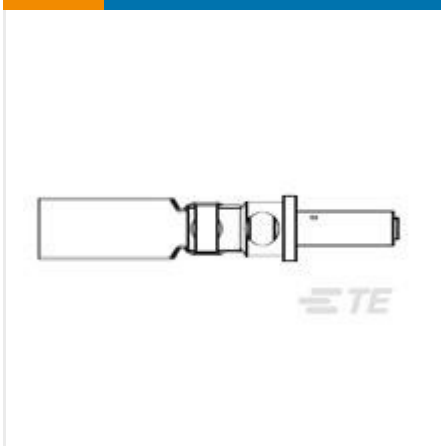

✓ Active

TE CONNECTIVITY (TE)

D-602-54

Raychem

601037-000

TE Internal Number: 601037-000

Alias ID: 1-1194756-1

Not Yet Reviewed for EU RoHS

Not Yet Reviewed for EU ELV

Product Type Contact

Wire/Cable Type Twisted Pair

Contact Style Pin

Contact Size 16

Wire Size Range (AWG) 30 – 24



PRODUCT DRAWING

English

DOCUMENTATION

Product Drawings

Shield Contact, Pin Twisted Pair

PDF

English

Product Specifications

Product Specification

SolderTact Military-Grade Electrical Contacts For Solder Termination

PDF

English

Termination Procedure For 748 Series SolderTacts Contacts For Twisted Pair Cable D-602-54, D-602-55

PDF

English

Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Product Type Contact

Wire/Cable Type Twisted Pair

Contact Features

Contact Style Pin

Contact Size 16

Termination Features

Termination Method Solder

Dimensions

Wire Size Range (AWG) 30 – 24

Usage Conditions

Operating Temperature (Max) (°C) 125

Industry Standards

Government Qualified No

Military Standard MIS-20065, MIS-20067/4

Statement of Compliance

Statement of Compliance

PDF