




TE Connectivity: Every Connection Counts
© 2017 TE Connectivity Ltd. family of companies. All Rights Reserved

HEAT SHRINK TUBING

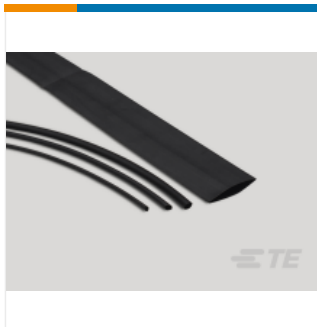

✓ Active

TE CONNECTIVITY (TE)

X2-3.0-0-SP

Raychem | SWFR X2

EJ1481-000

TE Internal Number: EJ1481-000

EU RoHS Compliant

EU ELV Compliant

Wall Type Single

Resistant To Abrasion

Low Outgassing No

Product Source US

Packaging Method Spool

↓ **PRODUCT DRAWING**
English

DOCUMENTATION

Product Drawings

SWFR X2 SINGLE WALL HEAT SHRINKABLE TUBING

PDF

English

Catalog Pages/Data Sheets

1-1773894-4_SWFR_Tubing

PDF

English

Highly Flame-Retardant, Zero Halogen, Low Recovery Temperature, Metric-Sized Heat-Shrinkable Tubing

PDF

English

FEATURES



Please review product documents or [contact us](#) for the latest agency approval information.

Please Note: Use the Product Drawing for all design activity.

Product Type Features

Wall Type Single

Product Family X2

Electrical Characteristics

Voltage (Max) (kV) .6

Body Features

Shrink Ratio 2:1

Color Black

Flexibility Very Flexible

Material ZEROHAL Polyolefin

Fluid Type Water

Dimensions

Recovered Wall Thickness (Nominal) .44 mm [.017 in]

Expanded Inside Diameter (Min) 3.6 mm [.142 in]

Recovered Inside Diameter (Max) 1.5 mm [.059 in]

Usage Conditions

Resistant To Abrasion

Recovery Temperature (°C) 90

Operating Temperature Range (°C) -55 – 105

Flammability Flame-Retardant

Shrink Temperature (Min) (°C) 70

Fluid Resistance Moisture/Spray Protection

Product Availability

Applicable Region Global

Packaging Features

Packaging Method Spool