


Nylon Hex Nuts

MENU

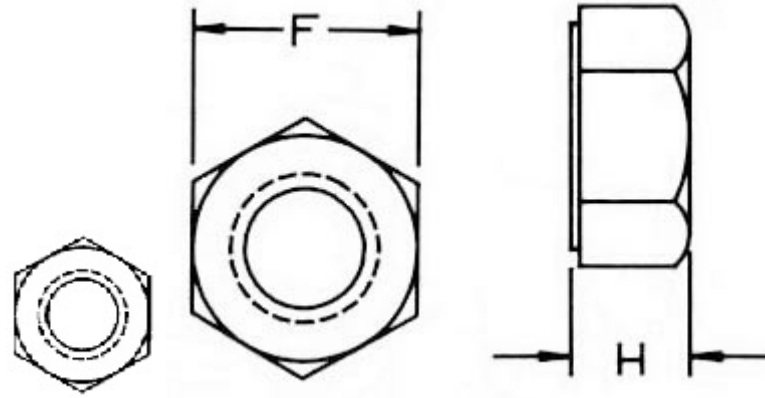

Stocked in Nylon 6/6 UL 94V2 - Can be furnished in: Acetal

The F and H dimension of following parts measure to IFI specifications:

- 0425020HN
- 0425028HN
- 0450020HN



[Filter List](#) [Advanced Sort](#) [Display Options](#)

Item Number	Description	Package Qty	F	H
0400256HN	256 HEX NUT M01 .180 A/F X .070 HT Pre-Packaged @ 1,000pcs/T-bag	1000	0.180 [4,57] (+/- 0.010)	0.070 [1,78] (+/- 0.010)
0400348HN	348 HEX NUT M01 .180 A/F X .070 HT Pre-Packaged @ 1,000pcs/T-bag	1000	0.180 [4,57] (+/- 0.010)	0.070 [1,78] (+/- 0.010)
0400440HN	440 HEX NUT M01 .250 A/F X .100 HT Pre-Packaged @ 1,000pcs/T-bag	1000	0.250 [6,35] (+/- 0.010)	0.100 [2,54] (+/- 0.010)
0400632HN	632 HEX NUT M01 .305 A/F X .120 HT Pre-Packaged @ 1,000pcs/T-bag	1000	0.305 [7,75] (+/- 0.010)	0.120 [3,05] (+/- 0.010)
0400640HN	640 HEX NUT M01 Pre-Packaged @ 1,000pcs/T-bag	1000	0.305 [7,75] (+/- 0.010)	0.120 [3,05] (+/- 0.010)
0400832HN	832 HEX NUT M01 .335 A/F X .130 HT Pre-Packaged @ 1,000pcs/S-Bag	1000	0.335 [8,51] (+/- 0.010)	0.130 [3,30] (+/- 0.010)
0401024HN	1024 HEX NUT M01 .365 A/F X .135 HT Pre-Packaged @ 1,000pcs/S-bag	1000	0.365 [9,27] (+/- 0.010)	0.135 [3,43] (+/- 0.010)
0401032HN	1032 HEX NUT M01 .365 A/F X .135 HT Pre-Packaged @ 1,000pcs/S-bag	1000	0.365 [9,27] (+/- 0.010)	0.135 [3,43] (+/- 0.010)
0401224HN	1224 HEX NUT M01 .425 A/F X .207 HT Pre-Packaged @ 1,000pcs/S-Bag	1000	0.425 [10,80] (+/- 0.010)	0.207 [5,26] (+/- 0.010)
0410008HN	1-8 HEX NUT M01 1.47 A/F X .870 HT	N/A	1.470 [37,34] (+/- 0.010)	0.870 [22,10] (+/- 0.010)

1 2 3

Show Dimension Tolerances (Values in [] are Metric Conversions)

All tolerances +/- .010