



**STF Series
Bumpers/Stick-On Feet**




Specifications:

- Material: Polyurethane
- Adhesive: Rubber
- Color: Clear or Black
- Application Temperature: 65°F to 150°F

Features:

- Will not tarnish, scratch, or discolor any surface
- Easy to use - simply peel & stick
- Adhesion works best on a smooth, clean & dry surface
- Commonly used as rubber feet, cabinet stoppers, door stops & surface protectors


**Cylindrical
On A Pad**

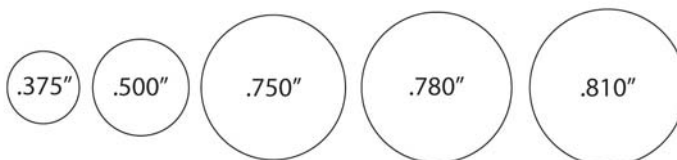

Actual Size (Diameter)

Item No.		Dia.		Height		Pieces/Pad	Pieces/Carton
Clear	Black	In	mm	In	mm		
RBS-34	RBS-34BK	0.375	9.5	0.125	3.2	300	6000
RBS-35	RBS-35BK	0.375	9.5	0.190	4.8	50	5000
RBS-5	RBS-5BK	0.500	12.7	0.060	1.5	200	5000
RBS-1	RBS-1BK	0.500	12.7	0.140	3.6	200	5000
RBS-6	RBS-6BK	0.500	12.7	0.250	6.4	50	5000
RBS-11	RBS-11BK	0.620	15.7	0.400	10.2	128	2560
RBS-44	RBS-44BK	0.750	19.1	0.160	4.1	98	2450
RBS-41	RBS-41BK	0.780	19.8	0.200	5.1	84	3360
RBS-24	RBS-24BK	0.810	20.6	0.120	3	72	2520
RBS-72	RBS-72BK	1.240	31.5	0.100	2.5	32	2400


**Hemisphere
On A Pad**

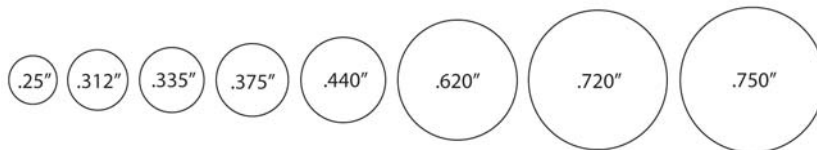

Actual Size (Diameter)

Item No.		Dia.		Height		Pieces/Pad	Pieces/Carton
Clear	Black	In	mm	In	mm		
RBS-40	RBS-40BK	0.250	6.4	0.062	1.6	578	15028
STFHEM250087A	STFHEM250087B	0.250	6.4	0.087	2.2	450	5400
RBS-27	RBS-27BK	0.312	7.9	0.085	2.2	450	5400
RBS-7	RBS-7BK	0.335	8.5	0.085	2.2	450	5400
RBS-12	RBS-12BK	0.375	9.5	0.150	3.8	72	7200
RBS-22	RBS-22BK	0.375	9.5	0.221	5.6	300	6000
RBS-10	—	0.390	9.9	0.120	3.0	288	7200
RBS-2	RBS-2BK	0.440	11.2	0.200	5.1	242	5082
RBS-15	RBS-15BK	0.620	15.7	0.310	7.9	128	3200
RBS-8	RBS-8BK	0.720	18.3	0.380	9.7	98	2254
RBS-37	RBS-37BK	0.720	18.3	0.560	14.2	100	1500
RBS-39	RBS-39BK	0.750	19.1	0.075	1.9	98	2254

**Square
On A Pad**

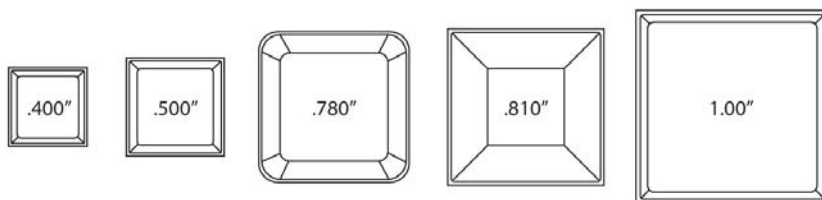

Actual Size (Width / Length)

Item No.		Dia.		Height		Pieces/Pad	Pieces/Carton
Clear	Black	In	mm	In	mm		
RBS-20	RBS-20BK	0.400	10.2	0.100	2.5	242	5082
RBS-32R	RBS-32RBK	0.500	12.7	0.120	3.0	200	5000
RBS-3R	RBS-3RBK	0.500	12.7	0.230	5.8	200	5000
RBS-4	RBS-4BK	0.750	19.1	0.340	8.6	100	5600
RBS-29	RBS-29BK	0.780	19.8	0.250	6.4	98	2940
RBS-19	RBS-19BK	0.810	20.6	0.300	7.6	98	2646
RBS-36	RBS-36BK	1.000	25.4	0.180	4.6	55	2310