



**Black Nylon Plunger Snap Latch Rivet -
Compatible Hole Diameter Range 4.45 - 4.65 mm |
0.175 - 0.183 in; Compatible Door Thickness Range
2.5 - 4.5 mm | 0.098 - 0.177 in; Compatible Part
NumbersSLG-2S-B**

Item code: **SLPB-2S-B**

● 296 In stock


This snap latch plunger is made from black Nylon and is rated to UL94 V-2. For use with the corresponding plunger SLG-2S-B (Sold separately).




[Download CAD](#)

Order sample:

[Add sample +](#)

[Print page](#) 

 Need a quote?

For large volumes and customised products, add to your cart and click request a quote, or email sales@essentracomponents.co.uk. Once received we will respond within 1 working day

**Can't find what you're looking for?
Tell us what you are looking for...**

Send us your enquiry and we will aim to get back to you in 1 business day

[Contact us](#)

[Request a quote](#)


Specifications Imperial Metric

Material	Nylon
Colour	Black
Type	Plunger
Rivet Type	Snap Latch
Compatible Hole Diameter Range	4.45 - 4.65 mm
Head Diameter	6.5 mm


Overall Width	6.5 mm
Compatible Door Thickness Range	2.5 - 4.5 mm
Compatible Part Numbers (All)	SLG-2S-B
Material Flammability Standard	UL94 V-2
Full Material	Nylon 6/6

Useful Information

Documents

 [Technical Drawing - SLPB-2S-B \(P021095\)](#)

Recently viewed items

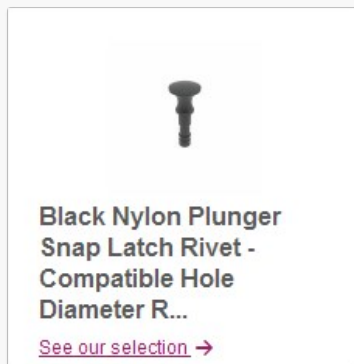

[BACK TO TOP](#) ^

Information Legal Policies

[Contact Us](#)

[About Us](#)

[Sustainability](#)

[Catalogues](#)

[Delivery & Returns Information](#)

[Careers](#)

[Quality Statement](#)

[Conditions of Sale](#)

[Privacy Policy](#)

[Health and Safety](#)

[Modern Slavery](#)

[Statement](#)

Legal Policies

[Terms of Use](#)

[Cookie Policy](#)

[Promotion Terms](#)

[GDPR](#)

[Order Cancellation](#)

Contact Us

Tel: 0845 758 5070 

Email: sales@essentracomponents.co.uk 

