



micro plastics, inc.

quality plastic fasteners for over 50 years



Select Your Region: United States

TOLL FREE: 800-466-1467

Customer Login

MENU

HOME

CATALOG

COMPANY
INFO

TECHNICAL
DATA

CAPABILITIES

CONTACT US

DISTRIBUTORS

CUSTOM
MOLDING

CUSTOMERS



Browse Search Results for '010440F018'

Search

Need Help?


Select Product Family



Select Product Category

View Item Detail - 1 Items Found

Slotted Fillister Mach Screw

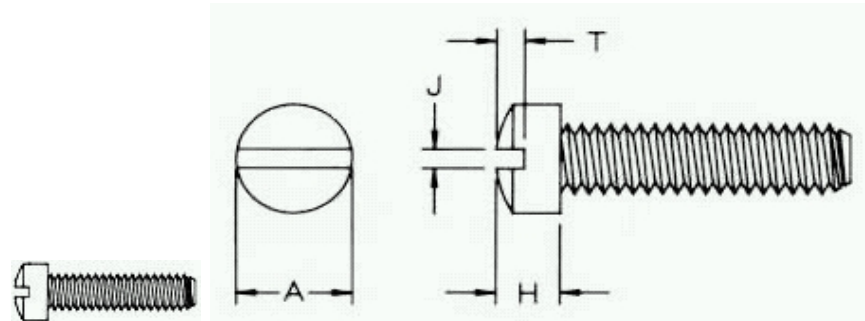

[Filter List](#) [Advanced Sort](#) [Display Options](#)

Item Number	Description	Thread Size	A	H	J	T	Length
010440F018	440 3/16 FILLISTER SLOTTED M01	440	0.166 - 0.183	0.088 - 0.107	0.031 - 0.039	0.035 - 0.048	0.187 (+ 0.000/- 0.020)

Show Dimension Tolerances

Nominal Screw Size	0000 thru 00	0 thru 12	1/4 thru 3/4
Nominal Screw Length	Tolerance on Length		
Up to 1/2 in., incl.	-0.01	-0.02	-0.03
Over 1/2 to 1 in., incl.	-0.02	-0.03	-0.03
Over 1 to 2 in., incl.	-	-0.06	-0.06
Over 2 in.	-	-0.09	-0.09

[HOME](#) : [CATALOG](#) : [FULL CATALOG](#)

Best Viewed in IE 6, Firefox 2, Opera 9, and Safari 1 (listed versions or later)
Recommended Screen Size of 1024 x 768 (or larger)

2007 - 2009 Micro Plastics, Inc. All Rights Reserved