
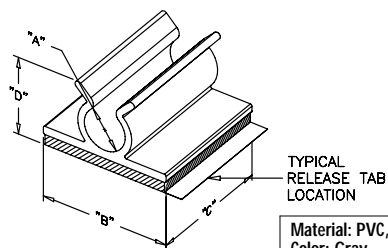


WIRE ROUTING, CLIPS & CLAMPS

KKU Kwik Klip Type "U"

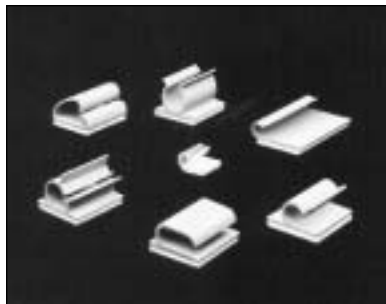


Material: PVC, RMS-04 • Adhesive Back, 1/16" (1.59mm) thick, RMS-15
Color: Gray

Part No.	Holding Capacity "A"	"B" ±.015 (0.4)	"C" ±.03 (0.8)	"D" At Max Capacity Ref.	Standard Pack
KKU-2-RT	1/8 (3.2)	3/4 (19.1)	3/4 (19.1)	9/32 (7.1)	500
KKU-4-RT	1/4 (6.4)			15/32 (11.9)	
KKU-6-RT	3/8 (9.5)			19/32 (15.1)	
KKU-8-RT	1/2 (12.7)	1 (25.4)	1 (25.4)	11/16 (17.5)	100
KKU-9-RT	9/16 (14.3)			3/4 (19.1)	
KKU-12-RT	3/4 (19.1)			29/32 (23.0)	
KKU-14-RT	7/8 (22.2)			31/32 (24.6)	

Also available in clear PVC, RMS-32 by special order.
Custom lengths available by special order.

KKD Kwik Klip Type "D"

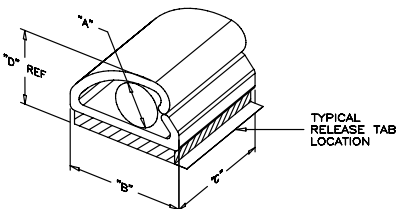


Material: PVC, RMS-04 • Adhesive Back, 1/16" (.4mm) thick, RMS-15
Color: Gray

Part No.	Holding Capacity "A"	"B" ±.02 (0.5)	"C" ±.03 (0.8)	"D" At Max Capacity Ref.	Standard Pack
KKD-4-RT	1/4 (6.4)	1/2 (12.7)	1/2 (12.7)	.40 (10.2)	500
KKD-8-RT	1/2 (12.7)	3/4 (19.1)	3/4 (19.1)	.73 (18.5)	100
KKD-12-RT	3/4 (19.1)	1 - 1/8 (28.6)	1 (25.4)	1.02 (25.9)	
KKD-16-RT	1 (25.4)	1 - 1/2 (38.1)	1 - 1/4 (31.8)	1.30 (33.0)	

Also available in clear PVC, RMS-32 by special order.
Custom lengths available by special order.

KKDL Kwik Klip Type "DL" - Locking

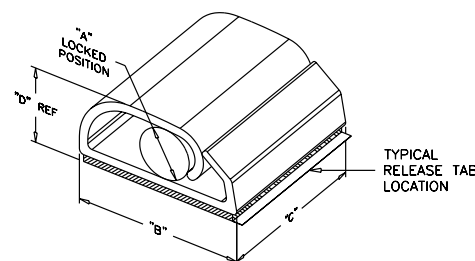

Material: PVC, RMS-04 • Adhesive Back, 1/16" (.4mm) thick, RMS-15
Color: Gray

Part No.	Holding Capacity "A"	"B" ±.015 (0.4)	"C" ±.03 (0.8)	"D" At Max Capacity Ref.	Standard Pack per bag
KKDL-4-RT	1/8 (3.2)	1/2 (12.7)	1/2 (12.7)	.28 (7.1)	500
KKDL-8-RT	7/32 (5.6)	3/4 (19.1)	3/4 (19.1)	.43 (10.9)	100

Also available in clear PVC, RMS-32 by special order.
Custom lengths available by special order.

KKL Kwik Klip Type "L" - Locking

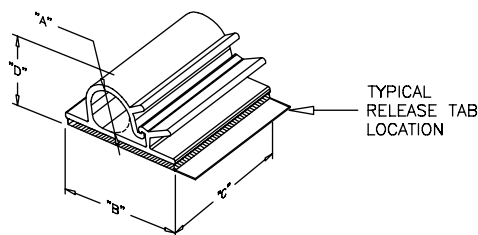


Fig. 1

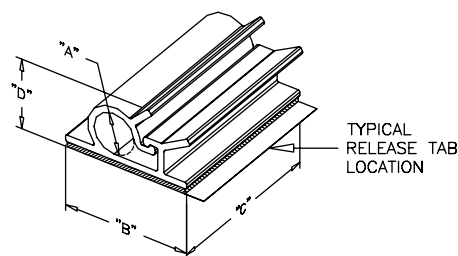


Fig. 2

Material: PVC, RMS-04 • Adhesive Back, 1/16" (.4mm) thick, RMS-15
Color: Gray

Part No.	Holding Capacity "A"	"B" ±.015 (0.4)	"C" ±.03 (0.8)	"D" At Max Capacity Ref.	Fig. No.	Standard Pack
KKL-4-RT	1/4 (6.4)	3/4 (19.1)	3/4 (19.1)	9/16 (14.3)	1	500
KKL-8-RT	1/2 (12.7)	1 (25.4)	1 (25.4)	27/32 (21.4)	2	100
KKL-12-RT	3/4 (19.1)			1 (25.4)		

Also available in clear PVC, RMS-32 by special order.
Custom lengths available by special order.