




## TREE CLIP SERIES 167-2



- Made From Nylon-66 (PA66)
- Colour: natural, black
- Design enables reliable fitting in variable hole size
- Hole size min = A, max =B

### Dimensions

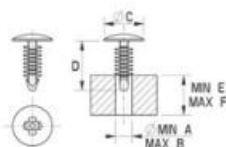

Dimensions in mm

Article number	Colour	A	B	C	D	E	F	Pc	Pr	Pe	P	e	Pr	
167 2010 000 02		2.7	3.3	6	7	1.5	4	65.15	1000	42.18	500	11.89	100	
167 2010 699 02		2.7	3.3	6	7	1.5	4	65.15	1000	42.18	500	11.89	100	
167 2015 000 02		2.7	3.3	6	11	1.5	8	68.18	1000	44.15	500	12.44	100	
167 2015 699 02		2.7	3.3	6	11	1.5	8	68.18	1000	44.15	500	12.44	100	
167 2020 000 02		2.7	3.3	6	18	1.5	15	85.20	1000	55.17	500	15.55	100	
167 2020 699 02		2.7	3.3	6	18	1.5	15	85.20	1000	55.17	500	15.55	100	
167 2030 000 02		3.3	4.2	10	8	1.5	4.5	110.38	1000	71.47	500	20.15	100	
167 2030 699 02		3.3	4.2	10	8	1.5	4.5	110.38	1000	71.47	500	20.15	100	
167 2040 000 02		4.1	5.2	12	6	1	2.5	99.31	1000	64.30	500	18.13	100	
167 2040 699 02		4.1	5.2	12	6	1	2.5	99.31	1000	64.30	500	18.13	100	
167 2045 000 02		4.1	5.2	12	10	1.5	5.5	101.69	1000	65.85	500	18.56	100	
167 2045 699 02		4.1	5.2	12	10	1.5	5.5	101.69	1000	65.85	500	18.56	100	
167 2050 000 02		4.1	5.2	12	15	2	10	102.65	1000	66.47	500	18.73	100	
167 2050 699 02		4.1	5.2	12	15	2	10	102.65	1000	66.47	500	18.73	100	
167 2060 000 02		5.6	6.4	13	12	2	7	97.26	1000	62.98	500	17.75	100	
167 2060 699 02		5.6	6.4	13	12	2	7	97.26	1000	62.98	500	17.75	100	
167 2065 000 02		5.6	6.4	13	20	1.5	15	100.66	1000	65.17	500	18.37	100	
167 2065 699 02		5.6	6.4	13	20	1.5	15	100.66	1000	65.17	500	18.37	100	
167 2070 000 02		5.6	6.4	13	32	1	27	106.45	1000	68.92	500	19.43	100	
167 2070 699 02		5.6	6.4	13	32	1	27	106.45	1000	68.92	500	19.43	100	
167 2080 000 02		5.9	7.2	17	11	2	5.5	98.33	1000	63.67	500	17.95	100	
167 2080 699 02		5.9	7.2	17	11	2	5.5	98.33	1000	63.67	500	17.95	100	
167 2085 000 02		5.9	7.2	17	15	1	10	112.33	1000	72.73	500	20.50	100	
167 2085 699 02		5.9	7.2	17	15	1	10	112.33	1000	72.73	500	20.50	100	
167 2090 000 02		5.9	7.2	17	24	2	19	134.83	1000	83.93	500	21.91	100	
167 2090 699 02		5.9	7.2	17	24	2	19	134.83	1000	83.93	500	21.91	100	
167 2100 000 02		6.8	8.3	13	14	1.5	9	134.74	1000	83.87	500	21.89	100	
167 2100 699 02		6.8	8.3	13	14	1.5	9	134.74	1000	83.87	500	21.89	100	

PHONE: ++ 31 (0) 20 6868711 · FAX: ++ 31 (0) 20 6822567 · WWW.SKIFFY.COM