

Data sheet

OpDAT REGpro front cover 3RU, 7HP 12xST SM + MM (ceramic)

Page 1/4

P/N
15024A0112-E


EAN 4250184130369

2018-18-01

Illustrations



Dimensional drawing

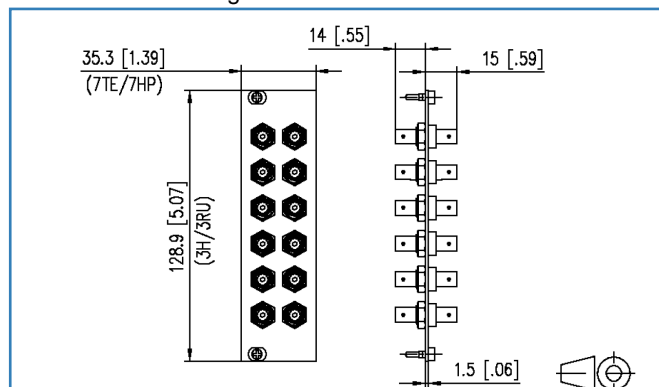

See enlarged drawings at the end of document

Product specification

- front plate 3RU/7HP with 12 ST adapters
- slotted ceramics sleeve for single mode and multi mode applications
- suitable for mounting in OpDAT REGpro and OpDAT REG S
- gray, powder-coated steel sheet

Technical Data

General Data

Fields of application	Structured building cabling
Design	Front cover
Mounting style	3RU/7HP
Transmission technology	Fiber optic
Color	metallike
Dimensions	
Dimension (L x W x H)	30.50 x 128.90 x 35.30 mm
Dimension (L x W x H)	1.201 x 5.075 x 1.39 in.
Height unit	3RU
Horizontal pitch	7Units
Mode type of the fiber	Singlemode + Multimode

Connections/interfaces

Connector technology interface 1	ST Couplers
Connector technology interface 2	ST Couplers
Number of ports interface 1	12
Number of ports interface 2	12
Number of equipped ports interface 1	12
Number of ports interface 2 equipped	12
Number of ports with dust protection interface 1	12
Number of ports with dust protection interface 2	12

Mechanical characteristics

Cut-out	ST
Connector type	Simplex
Life - Number of mating cycles	min. 1000

Materials and material properties

Material - Mounting plate	steel
Material - Mounting plate finish	powder-coated
Material - Sleeve	ceramic, slotted
Material - Coupler housing	Plastics

Technical Data

Approvals

RoHS compliant

The product meets the following standards

Fibre optic connector interfaces DIN EN 61754-2

Classifications

ETIM 5.0 EC001130

ETIM 6.0 EC001130

Packing details

Type of packaging	1 pc(s) / plastic bag
Packaging unit - Weight (gram)	148.00 g
Packaging unit - Weight (pound)	0.33 lb
Packaging dimension (W x H x D)	160.00 x 100.00 x 380.00 mm
Packaging dimension (W x H x D)	6.299 x 3.937 x 14.961 in.



Illustrations

Dimensional drawing

