


Handles to Build Front Panel/Module Assembly

Schroff offers a wide variety of handles in several colors for various applications including VME, VME64x and cPCI.

- Features:**
- ▶ IEL/IET Insertion/Extractor Handles — IEEE 1101.10
 - ▶ Extractor Handle, Type 2C for VME Application
 - ▶ Static Handle (Fixed)



Static Handle Kit, VME Application — Fixed Plastic Handle Only

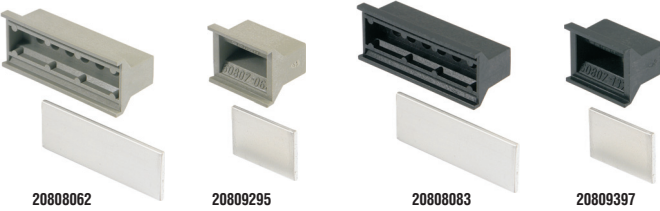


Note: Must be purchased in multiples of 5 pieces. Mounting hardware sold separately.

- Kit Contains:**
- ▶ Cantilever Plastic Handle, PPE, UL 94 V-1
 - ▶ Identification Plate, Al, 1.5 mm, Anodized, Cut Edges Plain

Stock No.	Mfr.'s Type	Color	Width (HP*)	EACH
70067524	20808062	Gray	8	3.27
70067526	20809295	Gray	4	1.61
70067525	20808083	Black	8	3.27
70067527	20809397	Black	4	1.83

Extractor Handles, VME Application — Type C

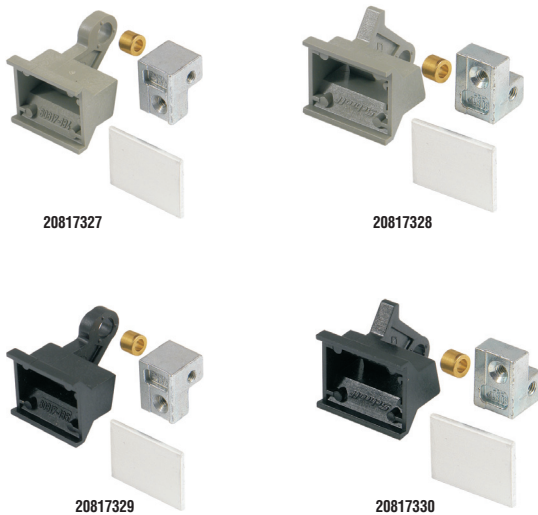

Sold only in multiples of 10 pieces.


- Kit Contains:**
- ▶ Separate Identification Plate
 - ▶ Cantilever Extractor Handle, PPE, UL 94 V-1, Gray and Black
 - ▶ Pivot Bushings, Printed Board Bracket
 - ▶ Cantilever Extractor Handle, PPE, UL 94 V-1, Gray and Black

Stock No.	Mfr.'s Type	Mounting	Color	EACH
70067528	20817327	Bottom Handle	Gray	5.31
70067529	20817328	Top Handle	Gray	5.31
70067530	20817329	Bottom Handle	Black	5.31
70067531	20817330	Top Handle	Black	5.31

AdvancedTCA Heavy-Duty Front Panels with IEA Handles and Hardware



- Features**
- ▶ Meet and Exceed all AdvancedTCA Standard Requirements
 - ▶ Die Cast End Pieces for Top and Bottom of Front Panel to Offer Increased Stability of Front Panel
 - ▶ Spring Loaded Handles
 - ▶ Textile EMC Shielding
 - ▶ Stainless Steel

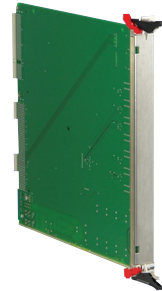

Stock No.	Mfr.'s Type	Size*†	Handle	Material	EACH
70067539	20818160	8U, 6 HP	Plunger Style	Stainless Steel	80.68
70294049	20818161	8U, 6 HP	Lever Style	Stainless Steel	62.55

AdvancedTCA Front Panels with IEA Handles and Hardware



- Features**
- ▶ Meet All AdvancedTCA Standard Requirements
 - ▶ Aluminum
 - ▶ Textile EMC Shielding



Stock No.	Mfr.'s Type	Size*†	Handle	Material	EACH
70294050	21596324	8U, 6 HP	Plunger Style	Stainless Steel	85.76
70294051	21596325	8U, 6 HP	Lever Style	Stainless Steel	61.48

IEL, Inject/Eject Handles to IEEE 1101.10, cPCI and VME64x — Kit



- Features:**
- ▶ Handle has Black Body with Gray Button
 - ▶ Will Accept a Hot-Swap Microswitch
 - ▶ Push-Button Locking Mechanism

- Kit Contains:**
- ▶ Die Cast Zinc with Integrated Alignment Pin and IEEE-1101.10 ESD/GND Pin
 - ▶ Lever, Plastic Key, Plastic Collar Screw, M2.5 x 12, 3 Nickel-Plated Steel
 - ▶ Pan Head Screw Phillips, M 2.5 x 7, Nickel-Plated Steel

Stock No.	Mfr.'s Type	Mounting	PER PKG./10
70067535	20817732	Bottom	60.01
70067536	20817734	Top	67.32

*HP = Horizontal Pitch, 1 HP = 0.20". †Units = Height Unit, 1U = 1.75" (44.45 mm).