



SCHROFF

Project - 0 item(s)

MY PROJECT LIST


- PRODUCTS
- APPLICATIONS
- INDUSTRIES
- NEW PRODUCTS
- CONFIGURATORS
- Products ▾
- Search
- 🔍

Home > End piece for guide rails for board height 4.4", red, groove width 2 mm



End piece for guide rails for board height 4.4", red, groove width 2 mm

SCHROFF

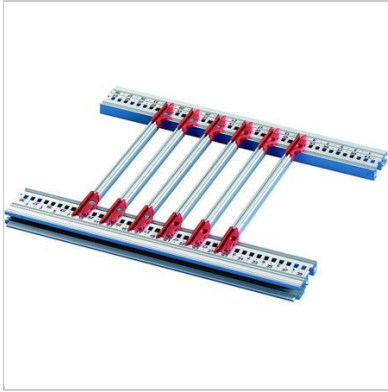

Catalog Number: 64560-057

[Back To Product](#)

- Fixed rail lengths can be made (160, 220, 280 and 340 mm) can be made with cut-out profiles, and with 1000 mm rails any length can be created.
- Can be clipped into horizontal rails in Al extrusion
- Storage temperature: from -40 °C ... 130 °C
- Guide rails for 2 mm groove width built with two plastic end pieces (red) and middle profile (plastic or Al extrusion)

Product family:

EuropacPRO

Note:

Delivery is in standard pack multiples. Pricing is per individual item

Type:

 
Individual Components

Individual Component Type:

Guide Rails & Accessories



Other Views



Select product specifications before modifying or adding to project list or requesting a quote.

[Clear Selection](#)

Quantity

Add Item to Project List +

Links

Native CAD files


Technical Data

Qty	1 piece (SPQ 10)
Delivery is exclusively made in Standard Pack Quantity (SPQ)	10
Color	red
Groove width	2.0

Delivery Comprises:

Item	Quantity	Description
1	2	End piece, red, plastic, PBT, UL 94 V-0

 
Accessories



Guide rails for plug-in units and modules

34560-894


Add Item to Project List +

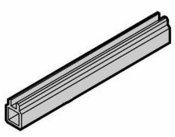

Guide rails for plug-in units and modules

34564-892


[Add Item to Project List +](#)

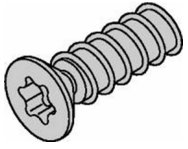

Countersunk screw, Torx (2.5x7.7), self-tapping, steel zinc plated, PU 100 pcs

24560-158


[Add Item to Project List +](#)

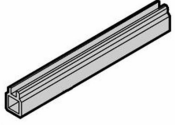

Countersunk screw, Torx (2.5x7.7), self-tapping, steel zinc plated, PU 100 pcs

34564-891

[Add Item to Project List +](#)

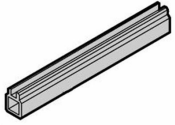

Countersunk screw, Torx (2.5x7.7), self-tapping, steel zinc plated, PU 100 pcs

34564-893

[Add Item to Project List +](#)

EXPLORE

- [About Us](#)
- [Services & Capabilities](#)
- [News & Events](#)
- [Newsletter Subscriptions](#)
- [Strategic Partnerships](#)
- [Investor Relations](#)

CONTACT

- [Customer Service](#)
- [Find a Sales Office or Distributor](#)
- [Global Locations](#)
- [Product Compliance & Certifications](#)
- [Partner Login](#)

DOWNLOAD

- [Download Center](#)
- [Reference Projects](#)
- [Videos](#)
- [Product Configurators](#)
- [Warranties and Terms of Sale & Procurement](#)

© 2018 nVent. All rights reserved | [Privacy Policy](#) | [Terms of Use](#) | [Cookie Policy](#) | [Imprint](#) | [Site Map](#)

Connect With Us

