


# Nylon Liquid Tight Strain Relief Fittings

## Reduced Body - PG Threads



### Reduced Body Strain Relief Fittings

Part Numbers				Cable Range	Thread Type & Size	Dimensions in Inches (mm)				
-40 °F to 212 °F (-40 °C to 100 °C)						Inches (mm)	See page 49 for thread specs	A	B	C
Dome Fittings		Flex Fittings		Clearance Hole	Body Length (Dome)			Body Length (Flex)	Thread Length	Wrench Flats
						+ .01" (+.25 mm)				
CD09BA-BK	CD09BA-GY	CF09BA-BK	CF09BA-GY	.11 - .26 (3-6.5)	PG 9	.60 (15.2)	.83 (21)	2.13 (54)	.31 (8)	.75 (19)
CD09BR-BK	CD09BR-GY	CF09BR-BK	CF09BR-GY	.08 - .20 (2-5)	PG 11	.73 (18.5)	.87 (22)	2.48 (63)	.31 (8)	.87 (22)
CD11BA-BK	CD11BA-GY	CF11BA-BK	CF11BA-GY	.16 - .31 (4-8)						
CD11BR-BK	CD11BR-GY	CF11BR-BK	CF11BR-GY	.08 - .24 (2-6)	PG 13 / 13.5	.80 (20.3)	.98 (25)	3.07 (78)	.35 (9)	.94 (24)
CD13BA-BK	CD13BA-GY	CF13BA-BK	CF13BA-GY	.20 - .39 (5-10)						
CD13BR-BK	CD13BR-GY	CF13BR-BK	CF13BR-GY	.11 - .28 (3-7)	PG 16	.89 (22.5)	1.06 (27)	3.54 (90)	.39 (10)	1.06 (27)
CD16BA-BK	CD16BA-GY	CF16BA-BK	CF16BA-GY	.24 - .47 (6-12)						
CD16BR-BK	CD16BR-GY	CF16BR-BK	CF16BR-GY	.20 - .35 (5-9)	PG 21	1.12 (28.4)	1.10 (28)	3.94 (100)	.43 (11)	1.30 (33)
CD21BA-BK	CD21BA-GY	CF21BA-BK	CF21BA-GY	.39 - .55 (10-14)						
CD21BR-BK	CD21BR-GY	CF21BR-BK	CF21BR-GY	.27 - .47 (7-12)						

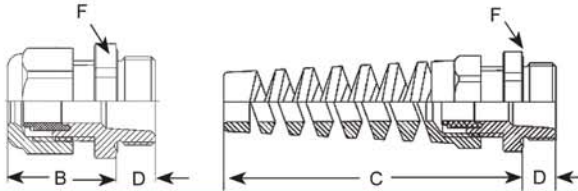

Suggested Clearance Hole for Non-Threaded Mounting



When your cable diameter **Decreases**, but your thread remains the same.

# Nylon Liquid Tight Strain Relief Fittings

## Enlarged Body - PG Threads



### Enlarged Body Strain Relief Fittings

Part Numbers				Cable Range	Thread Type & Size	Dimensions in Inches (mm)				
-40 °F to 212 °F (-40 °C to 100 °C)						Inches (mm)	See page 49 for thread specs	A	B	C
Dome Fittings		Flex Fittings		Clearance Hole	Body Length (Dome)			Body Length (Flex)	Thread Length	Wrench Flats
						+ .01" (+.25 mm)				
CD07GA-BK	CD07GA-GY	CF07GA-BK	CF07GA-GY	.16 - .31 (4-8)	PG 7 / 1/4" NPT	.49 (12.5)	.87 (22)	2.48 (63)	.31 (8)	.75 (19)
CD07GR-BK	CD07GR-GY	CF07GR-BK	CF07GR-GY	.08 - .24 (2-6)	PG 9	.60 (15.2)	.98 (25)	3.07 (78)	.31 (8)	.87 (22)
CD09GA-BK	CD09GA-GY	CF09GA-BK	CF09GA-GY	.20 - .39 (5-10)						
CD09GR-BK	CD09GR-GY	CF09GR-BK	CF09GR-GY	.11 - .27 (3-7)	PG 11	.73 (18.5)	.94 (24)	3.54 (90)	.31 (8)	.94 (24)
CD11GA-BK	CD11GA-GY	CF11GA-BK	CF11GA-GY	.24 - .47 (6-12)						
CD11GR-BK	CD11GR-GY	CF11GR-BK	CF11GR-GY	.20 - .35 (5-9)	PG 13 / 13.5	.80 (20.3)	1.10 (28)	3.94 (100)	.35 (9)	1.06 (27)
CD13GA-BK	CD13GA-GY	CF13GA-BK	CF13GA-GY	.39 - .55 (10-14)						
CD13GR-BK	CD13GR-GY	CF13GR-BK	CF13GR-GY	.27 - .47 (7-12)	PG 16	.89 (22.5)	1.22 (31)	4.49 (114)	.39 (10)	1.30 (33)
CD16GA-BK	CD16GA-GY	CF16GA-BK	CF16GA-GY	.51 - .71 (13-18)						
CD16GR-BK	CD16GR-GY	CF16GR-BK	CF16GR-GY	.35 - .63 (9-16)						

\*Note: UL f1 rating applies to Black Nylon Fittings only.



Optional Locking Nuts, O-Rings & Other Accessories starting on Page 28 - 39.

Dome Fittings also available with the following approvals:



www.sealconex.com



When your cable diameter **Increases**, but your thread remains the same.

For Material Specifications and Approval Information, please refer to page 45.