

Nylon Liquid Tight Strain Relief Fittings

Elongated - PG & Metric Threads




Part Numbers				Cable Range	Thread Type & Size	Dimensions in Inches (mm)				
-40 °F to 212 °F (-40 °C to 100 °C)						A	B	C	D	F ₁ /F
Dome Fittings		Flex Fittings		Inches (mm)	See page 49 for thread specs	Clearance Hole	Body Length (Dome)	Body Length (Flex)	Thread Length	Wrench Flats
Black	Gray	Black	Gray			+ .01" (+.25 mm)	(Elongated)			
CD07CA-BK	CD07CA-GY	CF07CA-BK	CF07CA-GY	.12 - .26 (3 - 6.5)	PG 7	.49 (12.5)	.83 (21)	2.13 (54)	.59 (15)	.59 (15)
CD07CR-BK	CD07CR-GY	CF07CR-BK	CF07CR-GY	.08 - .20 (2 - 5)						
CD09CA-BK	CD09CA-GY	CF09CA-BK	CF09CA-GY	.16 - .31 (4 - 8)	PG 9	.60 (15.2)	.87 (22)	2.48 (63)	.59 (15)	.75 (19)
CD09CR-BK	CD09CR-GY	CF09CR-BK	CF09CR-GY	.08 - .24 (2 - 6)						
CD11CA-BK	CD11CA-GY	CF11CA-BK	CF11CA-GY	.20 - .39 (5 - 10)	PG 11	.73 (18.5)	.98 (25)	3.07 (78)	.59 (15)	.87 (22)
CD11CR-BK	CD11CR-GY	CF11CR-BK	CF11CR-GY	.12 - .28 (3 - 7)						
CD13CA-BK	CD13CA-GY	CF13CA-BK	CF13CA-GY	.24 - .47 (6 - 12)	PG 13 / 13.5	.80 (20.3)	1.06 (27)	3.54 (90)	.59 (15)	.94 (24)
CD13CR-BK	CD13CR-GY	CF13CR-BK	CF13CR-GY	.20 - .35 (5 - 9)						
CD16CA-BK	CD16CA-GY	CF16CA-BK	CF16CA-GY	.39 - .55 (10 - 14)	PG 16	.89 (22.5)	1.10 (28)	3.94 (100)	.59 (15)	1.06 (27)
CD16CR-BK	CD16CR-GY	CF16CR-BK	CF16CR-GY	.28 - .47 (7 - 12)						
CD21CA-BK	CD21CA-GY	CF21CA-BK	CF21CA-GY	.51 - .71 (13 - 18)	PG 21	1.12 (28.4)	1.22 (31)	4.49 (114)	.59 (15)	1.30 (33)
CD21CR-BK	CD21CR-GY	CF21CR-BK	CF21CR-GY	.35 - .63 (9 - 16)						
CD29CA-BK	CD29CA-GY	-	-	.71 - .98 (18 - 25)	PG 29	1.47 (37.3)	1.54 (39)	-	.59 (15)	1.65 (42)
CD29CR-BK	CD29CR-GY	-	-	.51 - .79 (13 - 20)						
CD36CA-BK	CD36CA-GY	-	-	.87 - 1.26 (22 - 32)	PG 36	1.85 (47)	1.89 (48)	-	.71 (18)	2.09 (53)
CD36CR-BK	CD36CR-GY	-	-	.79 - 1.02 (20 - 26)						
CD42CA-BK	CD42CA-GY	-	-	1.26 - 1.50 (32 - 38)	PG 42	2.13 (54.1)	1.93 (49)	-	.71 (18)	2.36 (60)
CD42CR-BK	CD42CR-GY	-	-	.98 - 1.22 (25 - 31)						
CD48CA-BK	CD48CA-GY	-	-	1.46 - 1.73 (37 - 44)	PG 48	2.34 (59.4)	1.93 (49)	-	.71 (18)	2.56 (65)
CD48CR-BK	CD48CR-GY	-	-	1.14 - 1.38 (29 - 35)						

*Note: UL f1 rating applies to Black Nylon Fittings only.

*Note: VDE rating applies to Metric Fittings only.

Optional Locking Nuts, O-Rings & Other Accessories starting on Page 28 - 39.

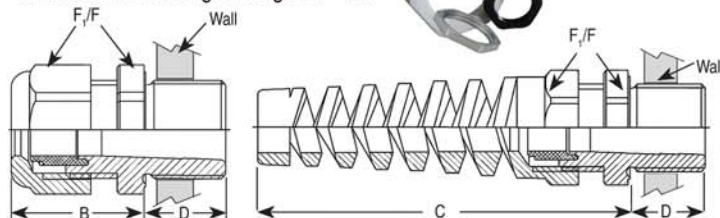

Dome Fittings also available with the following approvals:



www.sealconex.com

Elongated is recommended where the Strain Relief has to pass through a thick wall or the application just needs the Extra Thread Length.

CD12DA-BK	CD12DA-GY	CF12DA-BK	CF12DA-GY	.12 - .26 (3 - 6.5)	M12 x 1.5	.47 (12)	.83 (21)	2.13 (54)	.59 (15)	.59 (15)
CD12DR-BK	CD12DR-GY	CF12DR-BK	CF12DR-GY	.08 - .20 (2 - 5)						
CD16DA-BK	CD16DA-GY	CF16DA-BK	CF16DA-GY	.16 - .31 (4 - 8)	M16 x 1.5	.63 (16)	.87 (22)	2.48 (63)	.59 (15)	.75 (19)
CD16DR-BK	CD16DR-GY	CF16DR-BK	CF16DR-GY	.08 - .24 (2 - 6)						
CD17DA-BK	CD17DA-GY	CF17DA-BK	CF17DA-GY	.20 - .39 (5 - 10)	M16 x 1.5 Enlarged	.63 (16)	.98 (25)	3.07 (78)	.59 (15)	.87 (22)
CD17DR-BK	CD17DR-GY	CF17DR-BK	CF17DR-GY	.12 - .28 (3 - 7)						
CD20DA-BK	CD20DA-GY	CF20DA-BK	CF20DA-GY	.24 - .47 (6 - 12)	M20 x 1.5	.79 (20)	1.06 (27)	3.54 (90)	.59 (15)	.94 (24)
CD20DR-BK	CD20DR-GY	CF20DR-BK	CF20DR-GY	.20 - .35 (5 - 9)						
CD22DA-BK	CD22DA-GY	CF22DA-BK	CF22DA-GY	.39 - .55 (10 - 14)	M20 x 1.5 Enlarged	.79 (20)	1.10 (28)	3.94 (100)	.59 (15)	1.06 (27)
CD22DR-BK	CD22DR-GY	CF22DR-BK	CF22DR-GY	.28 - .47 (7 - 12)						
CD25DA-BK	CD25DA-GY	CF25DA-BK	CF25DA-GY	.51 - .71 (13 - 18)	M25 x 1.5	.98 (25)	1.22 (31)	4.49 (114)	.59 (15)	1.30 (33)
CD25DR-BK	CD25DR-GY	CF25DR-BK	CF25DR-GY	.35 - .63 (9 - 16)						
CD32DA-BK	CD32DA-GY	-	-	.71 - .98 (18 - 25)	M32 x 1.5	1.26 (32)	1.54 (39)	-	.59 (15)	1.65 (42)
CD32DR-BK	CD32DR-GY	-	-	.51 - .79 (13 - 20)						
CD40DA-BK	CD40DA-GY	-	-	.87 - 1.26 (22 - 32)	M40 x 1.5	1.57 (40)	1.89 (48)	-	.71 (18)	2.09 (53)
CD40DR-BK	CD40DR-GY	-	-	.79 - 1.02 (20 - 26)						
CD50DA-BK	CD50DA-GY	-	-	1.26 - 1.50 (32 - 38)	M50 x 1.5	1.97 (50)	1.93 (49)	-	.71 (18)	2.36 (60)
CD50DR-BK	CD50DR-GY	-	-	.98 - 1.22 (25 - 31)						
CD63DA-BK	CD63DA-GY	-	-	1.46 - 1.73 (37 - 44)	M63 x 1.5	2.48 (63)	1.93 (49)	-	.71 (18)	2.56 (65) / 2.68 (68)
CD63DR-BK	CD63DR-GY	-	-	1.14 - 1.38 (29 - 35)						

For Material Specifications and Approval Information, please refer to page 45.