

Industrial Cable Glands

[Inquiry](#)

Locations: [HUMMEL AG](#)

[Selected Products](#)

[Catalog Request](#)

search...

[Online Catalogue](#)

[Product Search](#)

[Enclosure-Configurator](#)

Home > Products > Industrial Cable Glands > HSK for special applications > HSK-MINI > 1.106.1001.50


[Print](#)

Online Catalogue

1.106.1001.50 **HSK-MINI / Metr.**



[add to list](#)

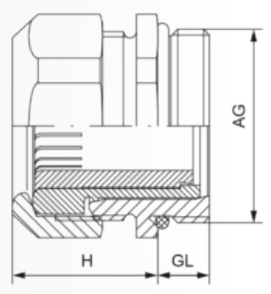

- Advice:**
- Other sealing material e.g. Silicone upon request
 - Other thread pitches on request
 - Stainless steel 1.4404 on request

Protection:	IP 68	Material	nickel-plated brass
O-Ring:	FFM	Male thread	M 10 x 1,5
	Buna-N	cable diameter	4 - 6 mm
		Thread Length	6 mm
		Wrench size	12 mm
		H	14 mm
		Seal ring material	TPE
		Operating-Temperature	-20 - 100 °C

[Next exhibit](#)