

3UB81334HW2 | 3UB81334HW2



Image similar

ESP200 Catalog NO 48BTH3S00 Solid state overload relay For motor protection 50 to 200Amp, Size B, 3 phase Class 5...30, switchable Direct mounting and stand-alone Main circuit: windows Auxiliary circuit scrw terminal Manual automatic reset

List Price Show prices

Customer Price Show prices

Additional Services For this product we can offer Services like Spare Part Delivery/Repair/Exchange. You have currently no rights to enter the Service Web Shop for that.  
For further information & to order this service, please contact your local Spares&Repair Partner

DataSheet in PDF Download

Service & Support (Manuals, Certificates, FAQs...) Download

Image gallery and data for M-CAD and E-CAD (1) (1)

Product data Further Product Information

Product	
Article Number (Market Facing Number)	3UB81334HW2   3UB81334HW2
Product Description	ESP200 Catalog NO 48BTH3S00 Solid state overload relay For motor protection 50 to 200Amp, Size B, 3 phase Class 5...30, switchable Direct mounting and stand-alone Main circuit: windows Auxiliary circuit scrw terminal Manual automatic reset

Product family	Overload Relays, Class 48, 958 and 3RB20
Product Lifecycle (PLM)	PM300:Active Product

Price data	
Price Group	UWW
List Price	Show prices
Customer Price	Show prices
Metal Factor	None

Delivery information	
Export Control Regulations	AL : N / ECCN : N
Standard lead time ex-works	30 Day/Days
Net Weight (lb)	0.772 lb
Product Dimensions (W x L x H)	Not available
Packaging Dimension	4.646 x 2.441 x 4.961
Package size unit of measure	in
Quantity Unit	1 Piece
Packaging Quantity	1

Additional Product Information	
EAN	4011209724907
UPC	662643854916
Commodity Code	8536490080
LKZ_FDB/ CatalogID	CC-IC10
Product Group	5439
Group Code	R711
Country of origin	Germany
Compliance with the substance restrictions according to RoHS directive	Since: 07/01/2006
Returnable	Yes
WEEE (2012/19/EU) Take-Back Obligation	No
REACH Art. 33 Duty to inform according to the current list of candidates	<ul style="list-style-type: none"> <li>Lead CAS-No. 7439-92-1 &gt; 0, 1 % (w / w)</li> <li>Lead monoxide (lead ... CAS-No. 1317-36-8 &gt; 0, 1 % (w / w)</li> </ul>

Classifications		
	Version	Classification
eClass	6	27-37-10-14
eClass	7.1	27-37-10-14
eClass	8	27-37-10-14
eClass	9	27-37-10-14
eClass	9.1	27-37-10-14
ETIM	6	EC002055
ETIM	7	EC002055
ETIM	8	EC002055
IDEA	4	5365
UNSPSC	14	39-12-23-30
UNSPSC	15	39-12-23-30




Buy product

Quantity 1 1 Piece

Add to cart


Frequently bought together:

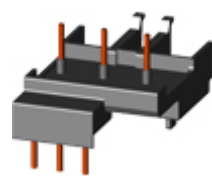

3RA19211DA00 |

3RA19211DA00

Link module Electrical and mechanical for 3RV2.1/3RV2.2 and 3RT2.1 AC and DC operation (individual unit packaging)

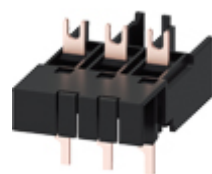

3RA29211AA00 |

3RA29211AA00

Link module for screw terminal electrical and mechanical for 3RV2.1/3RV2.2, and 3RT2.2. AC operation



3UG45131BR20 |

3UG45131BR20

Analog monitoring relay Phase failure and sequence Adjustable undervoltage Asymmetry 20% fixed 3 x 160 to 690 V 50 to 60 Hz AC Hysteresis 5% fixed Delay time 0-20 s 2 change-over contacts screw terminal Successor product for 3UG3013-1B...



3UG46151CR20 |

3UG46151CR20

Digital monitoring relay 3-phase supply voltage Phase sequence can be activated Phase failure 3 x 160 to 690 V 50 to 60 Hz AC Undervoltage and overvoltage 160-690 V Hysteresis 1-20 V 0-20 s each for Umin and Umax 1 CO for Umin 1 CO for Umax screw terminal Successor product for 3UG3041-1BP50



3LD25140TK53 |

3LD25140TK53

SENTRON, Switch disconnecter 3LD, emergency switching-off switch, 3- pole, Iu: 63 A, operating power / at AC-23 A 400 V: 22 kW, floor mounting with door coupling, rotary operating mechanism, Red / yellow, 4-hole mounting of the handle