





IPD1-10-D-K-M

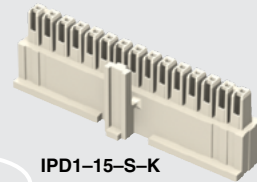

IPD1-15-S-K

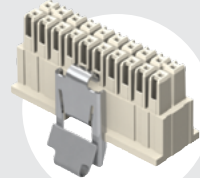

CC79L-2630-01-L

(2.54 mm) .100"

IPD1, CC79, PK-79 SERIES


# DISCRETE WIRE CABLE COMPONENTS

## SPECIFICATIONS

For complete specifications see [www.samtec.com?IPD1](http://www.samtec.com?IPD1) or [www.samtec.com?CC79](http://www.samtec.com?CC79)


## TOOLING

- Hand tool (20-30 AWG): CAT-HT-179-2030-13
- Mini Applicator (20-24 AWG): CAT-MA-179-2024-XX-01
- Mini Applicator (26-30 AWG): CAT-MA-179-2630-XX-01
- Extraction Tool: CAT-EX-179-01

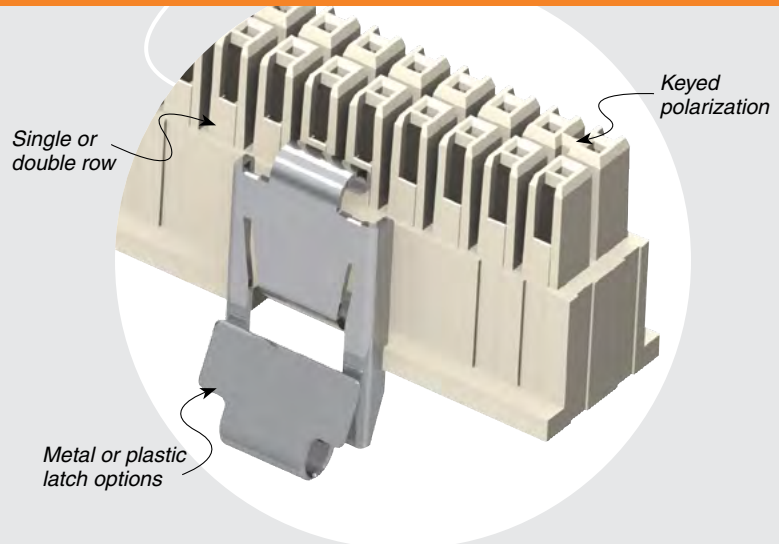


## PK-79


- Replaces the CC79 contact in the Mini Mate® housing (IPD1) for customizable polarization
- Plugs are molded black for better visibility against the white Mini Mate® housing
- PK-79 plugs are packaged in standard 50 pcs/bulk bag
- Handle is easily removed after insertion
- See [www.samtec.com?PK79](http://www.samtec.com?PK79) for complete specifications

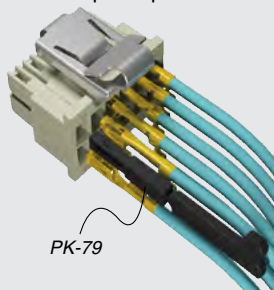

TYPE	POSITIONS PER ROW	ROW OPTION	K	LATCH OPTION	TYPE	WIRE GAUGE	01	PLATING OPTION
IPD1 = Body, Loose	-02, -03, -04, -05, -06, -08, -10, -12, -15, -16, -20, -25 (Standard sizes)	-S = Single Row  -D = Double Row	-K = Keyed Polarization	-M = Metal Latch (Metal for more rugged environments) (-02, -05 & -10 positions only) (Leave blank for plastic latch)	CC79L = Contact, Loose  CC79R = Contact, Full Reel (12,000 Parts per Reel)	-2630 = 26 to 30 AWG  -2024 = 20 to 24 AWG		-L = 10 μ" (0.25 μm) Gold on contact, Tin on tail

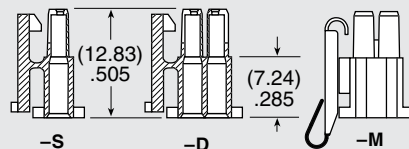

Insulator Material: Nylon 66

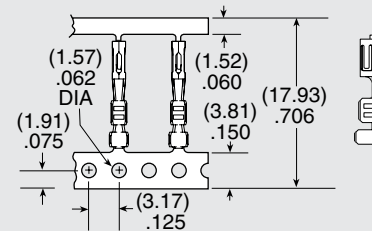

Contact Material: Phosphor Bronze