
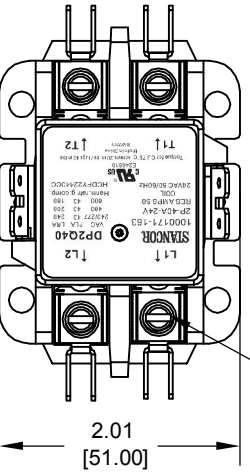
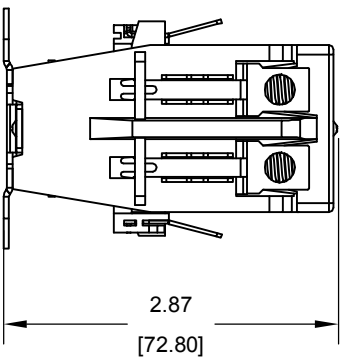
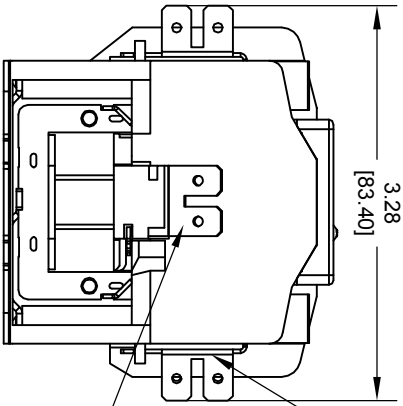
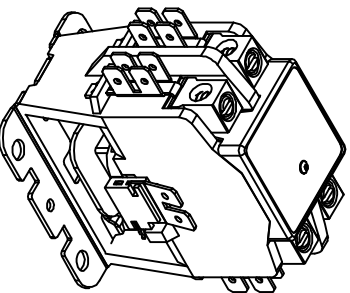


POLES	COIL VAC	FLA	RES	TERMINATION	COVER	INDIVIDUAL BOX
2	24VAC 50/60Hz	40	50	#14-4 COMPRESSION TERMINALS 4 Quick Connect Power Termination	YES	YES

COIL DATA
COIL 24VAC 50/60Hz 18 OHM 18 VAC OPERATE 3.8-16.3 VAC DROPOUT 32 VA INRUSH 5.6 VA SEAL MAX VOLTAGE 26.4 VAC


NOTES: UNLESS OTHERWISE SPECIFIED

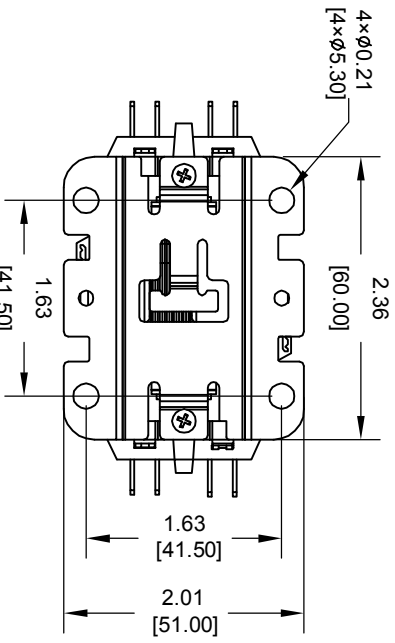

RANGE #14-4 AWG
CUI/L AWG BOX LUG (4 PCS)

4X 250X.032 MALE
QUICK CONNECTS
(4 PCS)


2XCOIL 250X.032 MALE
QUICK CONNECTS (2 PCS)

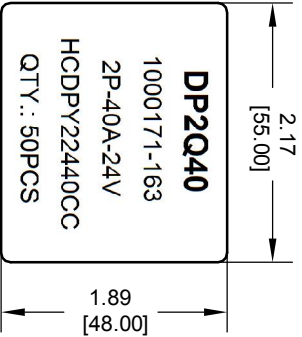

Master Carton Label



Product Label

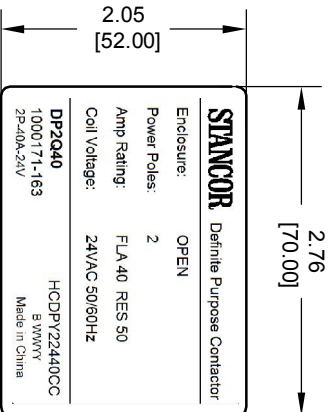

Individual Box Label

TOLERANCE
INCHES [mm]
X ±0.06 [1.50]
XX ±0.02 [1.50]
XXX ±0.006 [1.50]
X.XXX ±0.002 [0.50]
ANGLES ±1°

REV	DESCRIPTION	EGN	DMN	APPD	APPD DATE

DESC. 2P-40A-24V

PART NO. DP2Q40

STANCOR 2425 South 21st Street
Phoenix, AZ 85034
www.stancor.com (602)275-3800

DRAWN BY: DRAWN DATE: CHECKED BY: CHECKED DATE:

PAGE 1 OF 1