


Cylinder Type Polyacene Capacitors

PAS1840LA2R3566

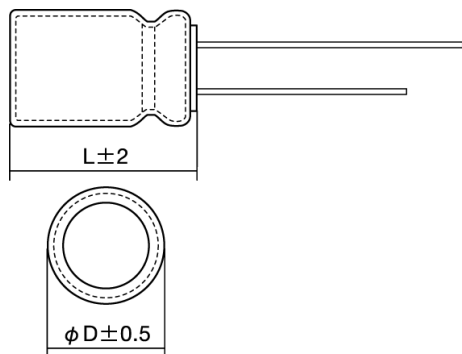

■ Features

- Item Summary
2.3V, 56F±20%, Less than 0.05Ω
- Lifecycle Stage
Phaseout

■ Products characteristics table

Temperature Range	-25 to +60°C
Maximum Usable Voltage	2.3V
Nominal Capacity	56F
Internal Resistance	0.05Ω
Initial Capacitance	56F±20%
Initial Internal Resistance	Less than 0.05Ω
RoHS Compliance	Yes
Soldering Method	Wave

2015.03.03

The data is reference only. Electrical characteristics vary depending on environment or measurement condition.
 TAIYO YUDEN reserves the right to make change to the Date at any time without notice.
 Before making final selection, please check product specification.