


Cylinder Type Polyacene Capacitors

PAS1235LA2R3226

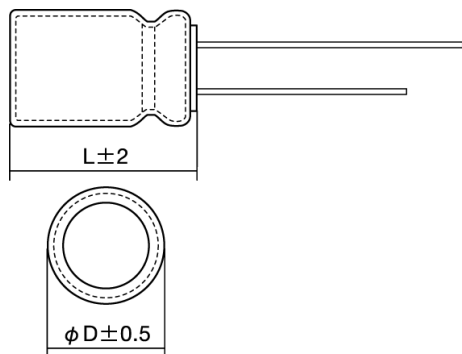

■ Features

- Item Summary
2.3V, 22F±20%, Less than 0.15Ω
- Lifecycle Stage
Phaseout
- Standard packaging quantity (minimum)
Bulk 50pcs

■ Products characteristics table

Temperature Range	-25 to +60°C
Maximum Usable Voltage	2.3V
Nominal Capacity	22F
Internal Resistance	0.15Ω
Initial Capacitance	22F±20%
Initial Internal Resistance	Less than 0.15Ω
RoHS Compliance	Yes
Soldering Method	Wave

2014.12.05

The data is reference only. Electrical characteristics vary depending on environment or measurement condition.
 TAIYO YUDEN reserves the right to make change to the Date at any time without notice.
 Before making final selection, please check product specification.