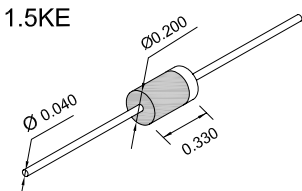


# Zener Diodes - 5W

# Zener

5W	Nominal Zener Voltage @ I <sub>ZT</sub>			Test Current	Max. Zener Impedance ( Ω )			Maximum Reverse Leakage Current I <sub>R</sub> @ V <sub>R</sub>		Package	Outline (Typ. in Inches)
	Nom.	Min.	Max.		Z <sub>ZT</sub> @ I <sub>ZT</sub>	Z <sub>ZK</sub> @ I <sub>ZK</sub>	I <sub>ZK</sub> (mA)	I <sub>R</sub> (μA)	V <sub>R</sub> (V)		
Part No.	V <sub>Z</sub> (V)	V <sub>Z</sub> (V)	V <sub>Z</sub> (V)	I <sub>ZT</sub> (mA)	Z <sub>ZT</sub> @ I <sub>ZT</sub>	Z <sub>ZK</sub> @ I <sub>ZK</sub>	I <sub>ZK</sub> (mA)	I <sub>R</sub> (μA)	V <sub>R</sub> (V)	Bulk/Reel	
1N5334B	3.6	3.42	3.78	350.0	3.0	500	1.0	150.0	1.0	1000/1400	
1N5335B	3.9	3.71	4.10	320.0	2.0	500	1.0	50.0	1.0		
1N5336B	4.3	4.09	4.52	290.0	2.0	500	1.0	10.0	1.0		
1N5337B	4.7	4.47	4.94	260.0	2.0	450	1.0	10.0	1.0		
1N5338B	5.1	4.85	5.36	240.0	2.0	400	1.0	10.0	1.0		
1N5339B	5.6	5.32	5.88	220.0	1.0	400	1.0	10.0	2.0		
1N5340B	6.0	5.70	6.30	200.0	1.0	300	1.0	10.0	3.0		
1N5341B	6.2	5.89	6.51	200.0	1.0	200	1.0	10.0	3.0		
1N5342B	6.8	6.46	7.14	175.0	1.0	200	1.0	10.0	5.2		
1N5343B	7.5	7.13	7.88	175.0	2.0	200	1.0	10.0	5.7		
1N5344B	8.2	7.79	8.61	150.0	2.0	200	1.0	10.0	6.2		
1N5345B	8.7	8.27	9.14	150.0	2.0	200	1.0	10.0	6.6		
1N5346B	9.1	8.65	9.56	150.0	2.0	150	1.0	7.5	6.9		
1N5347B	10	9.50	10.50	125.0	2.0	125	1.0	5.0	7.6		
1N5348B	11	10.45	11.55	125.0	3.0	125	1.0	5.0	8.4		
1N5349B	12	11.4	12.6	100.0	3.0	125	1.0	2.0	9.1		
1N5350B	13	12.35	13.65	100.0	3.0	100	1.0	1.0	9.9		
1N5351B	14	13.3	14.7	100.0	3.0	75	1.0	1.0	10.6		
1N5352B	15	14.25	15.75	75.0	3.0	75	1.0	1.0	11.5		
1N5353B	16	15.2	16.8	75.0	3.0	75	1.0	1.0	12.2		
1N5354B	17	16.15	17.85	70.0	3.0	75	1.0	0.5	12.9		
1N5355B	18	17.1	18.9	65.0	3.0	75	1.0	0.5	13.7		
1N5356B	19	18.05	19.95	65.0	3.0	75	1.0	0.5	14.4		
1N5357B	20	19.0	21.0	65.0	3.0	75	1.0	0.5	15.2		
1N5358B	22	20.9	23.1	50.0	4.0	75	1.0	0.5	16.7		
1N5359B	24	22.8	25.2	50.0	4.0	100	1.0	0.5	18.2		
1N5360B	25	23.75	26.25	50.0	4.0	110	1.0	0.5	19.0		
1N5361B	27	25.65	28.35	50.0	5.0	120	1.0	0.5	20.6		
1N5362B	28	26.6	29.4	50.0	6.0	130	1.0	0.5	21.2		
1N5363B	30	28.5	31.5	40.0	8.0	140	1.0	0.5	22.8		
1N5364B	33	31.35	34.65	40.0	10.0	150	1.0	0.5	25.1		
1N5365B	36	34.2	37.8	30.0	11.0	160	1.0	0.5	27.4		
1N5366B	39	37.05	40.95	30.0	14.0	170	1.0	0.5	29.7		
1N5367B	43	40.85	45.15	30.0	20.0	190	1.0	0.5	32.7		
1N5368B	47	44.65	49.35	25.0	25.0	210	1.0	0.5	35.8		
1N5369B	51	48.45	53.55	25.0	27.0	230	1.0	0.5	38.8		