



**Fork Terminal**  
**T&B Catalog Number:**

RA1123

**UPC Number:**

78621081759

**Status:**

Active

**Description:**

Nylon Insulated Fork Terminal, Length .83 Inches, Width .25 Inches, Maximum Insulation .136, Bolt Hole #8, Wire Range #22-#16 AWG, Color Red, Copper, Tin Plated


**WEB\_USE**

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

Inner bronze insulation grip sleeve lengthens flex radius of conductor and eliminates conductor creep. Nylon jacket is color-coded.

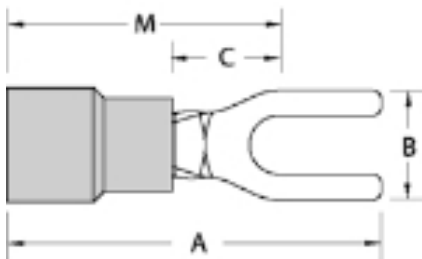

**General**

Insulation Type	Insulated Nylon
Terminal Series	RA
Material	Copper
Finish	Electro -Tin Plated
Color	Red
Wire Range	22-16
Stud Size	#8

**Dimension Information**

Maximum Insulation (inches)	.136
Stock Thickness	.03
A (inches)	.86
B (inches)	.31
C (inches)	.25
M (inches)	.71

**Specifications**

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2

**Tooling**

Tool Charts	Available on Website
Application Tools	WT145C, WT2000, WT112M, ERG4001, ERG4003, WT145A
Recommended Tool	ERG4001

**Packaging**

T&B Order Multiple	1000
T&B Inner Pack	1000
Package in Units	5000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	2.5 lbs. per 1000
Alternate Package Qty	RA18-8F

**Application Support**

Overview	Available on Website
----------	----------------------

Wire Guide Tables

Available on Website

## Notes

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk catalog numbers.

## Certifications

RoHS Compliance

Yes

## Certifications



File Nbr:

E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com