

Marrette® Set-Screw Vibration Proof / Visible Connection




The Marrette® Set-Screw is a two-piece, pressure type connector, featuring a solid brass insert with a screw-on insulating cap. It's the perfect choice when changing a motor, adding a circuit, conducting instrument testing or simply lashing-up temporary wiring.

External Cap

- Made of rugged, phenolic material and 150°C-rated.
- Insulator cap locks securely in place to safeguard against accidental loosening in high vibration applications.

Brass Insert

- Choice of Slot or Robertson Set Screw. When tightened into the insert, provides a solid pressure type connection on all approved wire combinations.
- No need to "re-strip" wires when rewiring. Simply loosen set screw to remove non-twisted wires.
- Special copper-coated spring helps resist corrosion.
- CSA (LR6591), UL (424H) - approved for circuits up to 600V, and lighting fixtures and signs up to 1000V.
- For copper wire only.
- Convenient packaging - sized right and job-site ready!

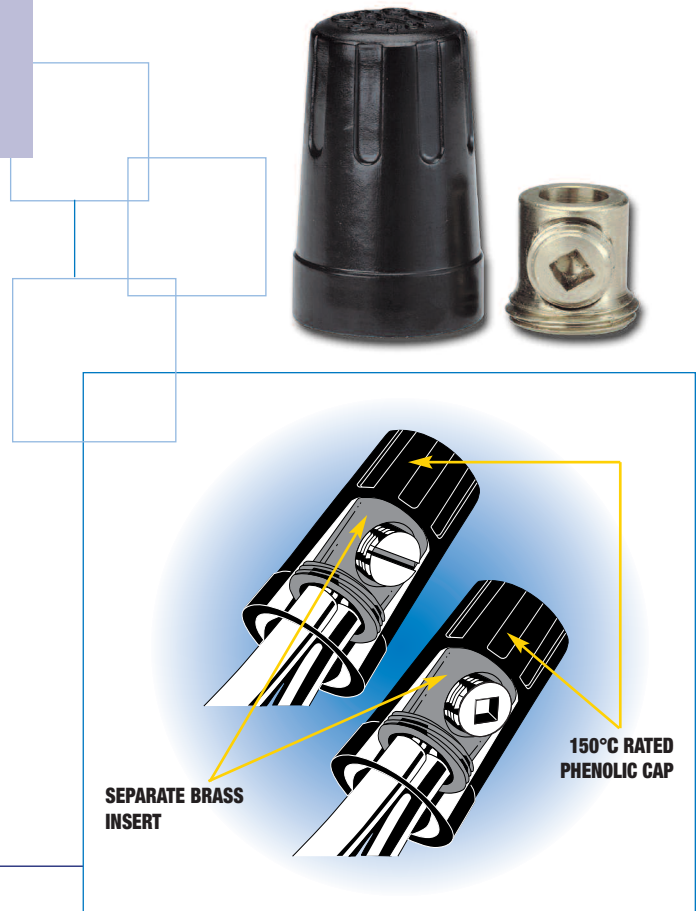

Ordering Information

Model	Screw Head	AWG Wire Range				
		16	14	12	10	8
1	Small slot-head.					
1i	Insert screw & brass barrel only.					
1SH	Small Robertson.					
1SHi	Insert screw & brass barrel only.					
2	Large slot-head.					
2i	Insert screw & brass barrel only.					
2SH	Large Robertson.					
2SHi	Insert screw & brass barrel only.					

Note: Refer to page 20 for related Wire Combination Reference Guide.



Packaging Options

Marrette® Set-Screw Vibration Proof / Visible Connection

marrette®

	Catalogue Number	Packaging Format	Quantity per Package	Std. Pkg. (Min./Mult.)
1	1P	Propak	100	1000
	1D	Flip-Pak	500	500
1SH	1SHP	Propak	100	1000
	1SHD	Flip-Pak	500	500
2	2P	Propak	50	500
	2D	Flip-Pak	500	500
2SH	2SHP	Propak	50	500
	2SHD	Flip-Pak	500	500
INSERT SCREWS AND BRASS BARRELS ONLY.				
1	1i	Carton	100	1000
1SH	1SHi	Carton	1000	1000
2	2i	Carton	50	1000
2SH	2SHi	Carton	1000	1000