

Color-Keyed®

Standard Barrel Copper Lug T&B Catalog Number:

54107UF

UPC Number:



78621086857

Status:

Active

Description:

Copper One-Hole Lug, 45 Degree Bend Standard Barrel, Peep Hole, Max 35kV, Wire Size #2 AWG, 1/4 Inch Bolt Size, Tin Plated, Die Code 33, Die Color Code Brown

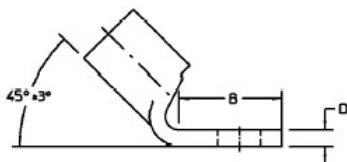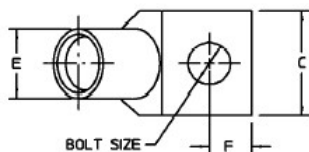

General

Material	Copper
Finish	Tin Plated
Wire Size	#2 AWG
Number of Studs	1
Stud Size	1/4
Tongue Angle	45
Barrel Length	Standard
Barrel Shape	Standard
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Brown
Die Code	33

Dimension Information

A (inches)	1.375
B (inches)	.563
C (inches)	.594
D (inches)	.125
E (inches)	.406
F (inches)	.25

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Inner Pack	25
Package in Units	250
T&B Sold in UOM	Each
T&B Weight Per UOM	2.94 lbs. per 100

Application Support

T&B Instruction Sheets	ta00675-tb2
Overview	Available on Website

Notes

Dimensions given for reference only. Dimensions may vary up to .030.

Certifications

RoHS Compliance Yes

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com