



Sta-Kon®

Locking Fork Terminal
T&B Catalog Number:

RA2213
 78621088732
 Active

UPC Number:
Status:
Description:

Insulated Nylon Locking Fork Terminal For Wire Range 22-16 Stud Size #6, Red

WEB_USE

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Locking fork terminals have a specially designed tongue that lets them go on like a fork and stay on like a ring.

General

Insulation Type	Insulated Nylon
Terminal Series	RA
Material	Copper
Finish	Electro -Tin Plated
Color	Red
Wire Range	22-16
Stud Size	#6

Dimension Information

Maximum Insulation (inches)	.136
Stock Thickness	.03
A (inches)	.86
B (inches)	.25
C (inches)	.25
M (inches)	.71

Specifications


Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	ERG4001, ERG4003, WT145C, WT2000, WT112M, WT145A
Recommended Tool	ERG4001

Packaging

T&B Order Multiple	1000
T&B Inner Pack	1000
Package in Units	10000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	0.22 lbs. per 100
Alternate Package Qty	RA18-6FL

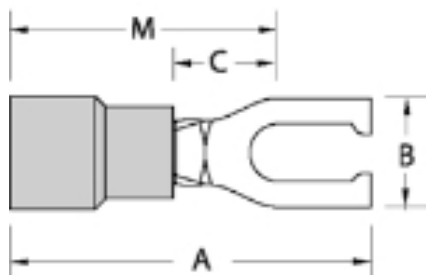

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Most terminals can be put on Mylar Tape for reel fed applications by adding the suffix M to the bulk catalog numbers.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com