


Please wait for menu to be constructed

Non-Metallic Sheathed Cable

Non-Metallic Sheathed Cable and Flexible Cord Connectors(Steel)

Two-screw Connectors

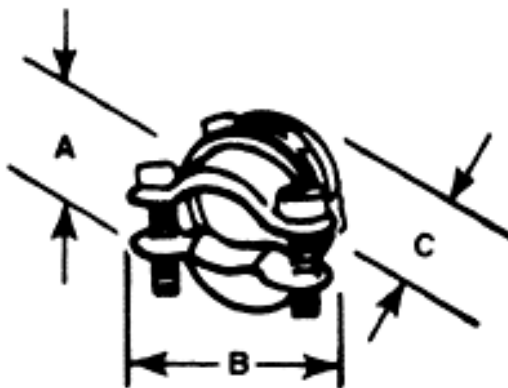

Steel or malleable iron.

Rounded cable grip and smooth bushing protect the cable sheath and wire insulation. Since saddle is threaded, screws do not travel or extend beyond the connector body as it is clamped to the cable. An extra lip on the saddle closes the unused part of the connector opening.

Dimension Information In F.P.S (U.S)

[Display in metric standards \(C.G.S\)](#)

Catalog No	A (In.)	B (In.)	C (In.)	Catalog No Ins	Catalog No Non Insul	Cbl Opng Max	Cbl Opng Min	Ko Size
3302	0.969	1.375	1.000	3302M	3302*	.59	.25	1/2"

Table Continued Below...

Catalog No	UI Listed1	UI Listed2
3302	(1) 2#14, 2#12, 2#10, 3#14, 3#12, 3#10, (2) 2#14, 2#12	2#12 thru 2#4, 3#12, 3#10

Packaging Information

Catalog#	Unit Quantity	Standard Quantity Package	Weight (lbs.)	Weight UOM
3302-TB	100	500	6.270	Per 100

Listed / Certified By



UL Listed

(Catalog# 3302-TB)
(File# 17583)



CSA Certified

(Catalog# 3302-TB)
(File# 2884000,4484000)

[View Product
Category](#)

[Print
Back](#)