



Ferrule
T&B Catalog Number:

F8010
78621033571
Active

UPC Number:
Status:
Description:


Insulated Nylon Twin Ferrule for Wire Size 2x12, Wire Size 2x4.00 mm², Length 0.906 inches, Grey

WEB_USE

US Cutsheet PDF Catalog Link <http://www-public.tnb.com/contractor/docs/stakon.pdf>

Features

Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.

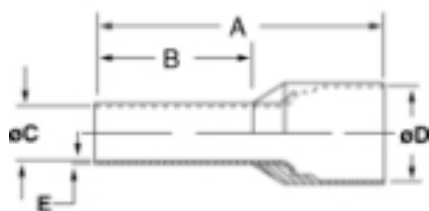

General

Ferrule Type	Insulated Twin
Insulation Type	Insulated Nylon
Material	Copper
Finish	Electro -Tin Plated
Color	Gray
Wire Range	2x12
Wire Size (mm ²)	2x4.00

Dimension Information

A (mm)	23.0
B (mm)	12.0
Diameter C (inches)	.150
Diameter C (mm)	3.8
Diameter D (inches)	.339
Diameter D (mm)	8.6
E (mm)	.15
A (inches)	.906
B (inches)	.472
E (inches)	.006

Specifications

Temperature Rating	105°C
Flammability Rating	UL 94 V-2

Tooling

Tool Charts	Available on Website
Application Tools	ERG4
Recommended Tool	ERG4

Packaging

T&B Order Multiple	100
T&B Inner Pack	100
Package in Units	1000
T&B Sold in UOM	Each
T&B Weight Per UOM	1.25 lbs. per 1000

Application Support

Overview	Available on Website
Wire Guide Tables	Available on Website

Notes

Ferrule dimensions conform to DIN 46228, Part 4.
6MM Die

Certifications

RoHS Compliance Yes

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com