



TRIPLETT
Test Equipment & Tools



POCKET REFERENCE



8000

CAMVIEW PTZ

Multi-Function CCTV & Security Camera Tester

- Full color 2.6" LCD video monitor
- Program and verify PTZ functions of CCTV's
- View camera output to adjust focus and field of view
- 10 hour rechargeable battery

CAMVIEW W35

Security Wrist Monitor with 3.5" Display

- Hands free operation allows for increase safety
- View camera output to adjust zoom, focus, position, etc.
- Daytime viewable display



8050

CAMVIEW W35v

Security Wrist Monitor with 12 volt output

- View camera output to adjust zoom, focus, position, etc.
- Power local security cameras with 12 volt output
- BNC loop through capabilities



8055

MODULEAD

Premium Modular Test Leads

- Universal design fits all digital multimeters
- Replace any test leads with premium modular leads
- Includes: 2 pointed probes, 2 flat nose probes, 2 alligator clips, 2 24" leads, 2 60" leads, & case



79-812



FIREFLY



3290

Rapid LAN Mapping Tool

- Identify LAN cables in a fraction of the time
- Slash LAN cable ID costs
- Basic kit includes transmitter and 100 remotes
- Add additional remotes for larger jobs

LOW VOLTAGE TESTING KIT

Premium Low Voltage Testing Kit

- Includes all equipment required for Low Voltage Testing
- Kit includes: 9007, Fox 2 & Hound 3, Plug-Bug 2, Sniff-It 2, 9200, Line-Bug 4, Pro Autoloader, Breaker Sniff-It in carrying case



TTK-LV

MAINTENANCE TESTING KIT

Premium Maintenance Testing Kit

- Includes all equipment required for Maintenance Testing
- Kit includes: 9045, 9310, TDR, Plug-Bug 2, Sniff-It 2, Pro Autoloader, Breaker Sniff-It in carrying case



TTK-MT

LAN TESTING KIT

Premium LAN Testing Kit

- Includes all equipment required for LAN Testing
- Kit includes: PairMaster, WireMaster XR-5, TDR, Fox 2 Hound 3, Pro AutoLoader, Line-Bug 4, in carrying case



TTK-LN



TRIPLETT

Test Equipment & Tools

ELECTRICAL TESTING KIT



TTK-EL

Premium Electrical Testing Kit

- Includes all the equipment an electrician needs
- Kit includes: 9007, 9310, Plug-Bug 2, Sniff-It 2, Pro Autoloader, Breaker Sniff-It in carrying case

Engineered for the Professional

Specialty Solutions



FOR MORE INFORMATION GO TO TRIPLETT.COM





PROFESSIONAL AUTOLOADER



TPAL-001

Auto loading screwdriver w/ 6 selectable bits contained in a heavy duty steel shaft.

- Patented pump action, changes bits quickly
- Comes preloaded with six commonly used industrial grade S2 bits
- Lighten load; carry one screwdriver on the job!

MINI AUTOLOADER

Precision auto loading screwdriver with 6 self contained bits.

- Precision AutoLoader, ideal for: Electrical workshops, watch repair and more!
- Comes with six commonly used bits
- Install thermostats, alarm panels, and more!



TMAL-001

INDUSTRIAL BIT KIT



TBK-001

32 piece Industrial Grade, 1/4" bit kit made of S2 steel

- Customize your AutoLoader to remove or install any fasteners
- Kit includes: Bit adapter for drill and carrying case with a belt clip

SECURITY BIT KIT

32 piece Industrial Grade, 1/4" bit kit for tamper proof fasteners

- Customize your AutoLoader to remove or install security fasteners
- Kit includes: Bit adapter for drill and carrying case with a belt clip



TSBK-001



CLIKGRIP



TT-220

7" Auto Adjusting Pliers

- Adjusts with only one hand
- Seamlessly adjust pliers to tackle any plumbing, heating, or automotive job with ease
- Rugged jaws help secure grip on nuts, washers, and bolts

CLIKGRIP

10" Auto Adjusting Pliers

- Adjusts with only one hand
- Seamlessly adjust pliers to tackle any plumbing, heating, or automotive job with ease
- Rugged jaws help secure grip on nuts, washers, and bolts



TT-221

POWRJAW

8" Electricians Pliers

- Perfect for electrical, plumbing, security, and alarm professionals
- PowrJaw delivers 100% gain in gripping power
- Pearl nickel finish resists corrosion
- Spring loaded and lockable handles



TT-230

POWRJAW

7.5" Diagonal Pliers

- Perfect for electrical, plumbing, security, and alarm professionals
- PowrJaw delivers 100% gain in cutting power
- Pearl nickel finish resists corrosion
- Spring loaded and lockable handles



TT-231

FOR MORE INFORMATION GO TO TRIPLETT.COM



POWERSTRIP



TT-240

Precision Automatic Wire Stripper

- Automatically strips wire from 8 to 30 AWG
- Easily crimps insulated and non-insulated terminals
- Built-in wire cutter

SUPRASTRIP

Precision Multifunction Wire Stripper

- Precision ground SK-5 steel jaws
- Strips 18 to 32 AWG standard wire
- Built-in wire cutter
- Wire loop bending holes



TT-241

CABLECUT



TT-242

Precision Electronic Cable Cutter

- Cuts multi-wire copper cable up to 3/8 diameter
- Built-in 10-20 AWG wire stripper
- Curved SK-5 steel cutting blades

POWERPRESS

Universal Compression Tool

- Make custom cables for your installation
- Make F cables for TV
- Make RCA cables for A/V
- Make BNC cables for CCTV and Security Cameras
- Works with all RG59 and RG6 cables



Coming Soon!

TT-250



TRIPLETT

Test Equipment & Tools

LONGLOCKER



TT-200

Extended reach 15" Locking Pliers

- Needle nose jaws can easily grip small objects
- Reach inaccessible fasteners and clips; saving valuable time
- Great for holding objects together for spot welds, screw driving, and more

CROSSJAW

Extended reach 13" Needle Nose Pliers

- Twin X double joint design; fits tighter spaces than conventional long reach pliers
- Flat rivet joint design give strength and arrow profile
- Parallel serrated tip provides precision gripping



Coming Soon!

TT-260

LASERTAPE 160



TLT-160

Non-contact Laser Measurement
from 2"-160'

- Easily calculate square footage, volume, and simple trig functions
- Add or subtract measurements
- 20 memory locations to save measurements
- Perfect for any type of room measurement

PROTEMP 12

Non-contact 12:1 Infrared Thermometer

- Measure surface temperature from a safe distance
- Laser, pinpoints measurement area
- Backlit display



PT12

FOR MORE INFORMATION GO TO TRIPLETT.COM



TSC-MC1

SONICHEK MC

Mini Sound Level Meter

- C weighted reads 40-130dB from 31.5Hz-8KHz
- Measure sound level of PA, home theater, alarm, sound systems, and more!
- Also features Min/Max and backlit display

FUEZR

Multi-purpose LED Work Lite with Case

- Easily add bright light to any installation
- 27 bright white LEDs
- Selectable 24 LED flood light or 3 LED flashlight
- Self storing hanger and adjustable stand
- 3 axis magnet arrangement



TT-101

GRABLITE

6 Bright LED Flashlight with a 21" Telescoping Flex End Magnet

- 21" magnetic tip can pick up dropped object, up to 2lbs
- Test magnetic switches, such as alarm systems
- Compact flashlight, to add light to any job



TT-110

CLIPLITE

Cap Lite with High Intensity White and Red LEDs with Adjustable Position

- Over visor design won't impair vision
- Adjustable angle puts light where it is needed
- Flashing LEDs improves safety for joggers



TT-120



BUGLITE



TT-130

Magnetic Base Multi-Purpose Light

- 2 bright white LEDs
- Magnet base attaches to flats, curves, or corners
- Attaches directly to tools
- Use several, can be placed on all sides to light up dark recesses

MIRROBRIGHT

34" Telescoping Lighted Inspection Mirror

- Easily see behind equipment
- 2 high intensity LED's for lighting
- Extend up to 34"
- Mirror size 3-1/2 x 2-1/4



Coming Soon!

TT-140

COBRACAM USB 2



8105

Portable Inspection Camera with USB Interface

- Save money; find problems before tear down
- Add visual access to tight spaces
- Snapshot and Live Video capable
- Works with Windows OS & MAC (Photo Booth)

COBRACAM 2

Portable, Self Contained, Inspection Camera with Video Monitor

- Gain visual access to inaccessible areas
- 2 high intensity LED's for lighting
- Use video monitor adaptor to help adjust CCTV 's
- Extend to 100' of watertight length with optional accessories



8115



FLEXSNAKE

3' Camera with 5.5mm Head for
CobraCam 2



CC2-CAM3FM

- 5.5mm head allows access to tight areas
- Extremely flexible shaft
- Excellent for tight spaces for your CobraCam 2
- Waterproof connections

REPLACEMENT CAMERA

Replacement Camera Wands for
CobraCam2


- CC2-CAM3F 3 foot camera wand
- CC2-CAM6F 6 foot camera wand
- CC2-CAM10F 10 foot camera wand
- Semi-rigid snake with 10.2mm head
- Waterproof connections



CAMERA EXTENSIONS

Extend the usefulness of your CobraCam2

- CC2-XC3F 3 foot extension
- CC2-XC6F 6 foot extension
- CC2-XC10 10 foot extension
- Combine cables to extend up to 100' without loss of resolution

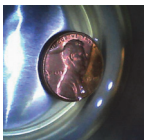



1101-B

Compact DMM with Backlit Display
and Temperature test

1101

- 3 1/2 digit backlit display
- 20 ranges including: Voltage, Current to 10A, Resistance, and Continuity
- Shock absorbing case with stand
- Diagnosis common wiring problems

2030-C

Auto-ranging Pocket Sized DMM

- Perfect for quick and accurate electrical readings
- Test batteries, solar cells, wall plugs, and power outlets
- Closing cover ensures unit is off; Saving battery life



2030



9007

Large 1.4" Backlit display DMM
w/ capacitance

9007

- Massive, 3 1/2 digit backlit display
- 31 ranges including: Voltage, Current to 20A, Resistance, Diode and Continuity
- Shock absorbing overmolded case with stand
- Perfect for electrical and alarm professionals

9045

True RMS DMM
w/Temp, Cap, and Frequency

- 6000 count auto ranging True RMS DMM w/Temp, Cap, and Frequency
- 61 segment bar graph
- Backlit display and overmolded case
- Perfect for electrical and alarm professionals



9045



ENVIROMETER

6 in 1 Digital Multimeter

- Built-in Light (Lux) and Sound Level (dB)
- Built-in Temperature and Relative Humidity
- 4000 count, fully annunciating, backlit display
- Shock absorbing, overmolded case w/ stand
- Perfect for alarm and HVAC professionals

9055

POWRCLAMP 9200

Mini AC Clamp-on meter

- Measure AC Amps from 0-300 amps
- Sensitive 20A range w/0.01 amp resolution
- Data hold function
- Carrying case included
- Quickly test wiring in security installations



9200

POWRCLAMP 9310

AC/DC Clamp-on Meter
w/Temp, Cap, Freq and Backlit display

- Measure AC/DC current with clamp-on
- Auto Ranging DMM measurements include: AC/DC Voltage, Capacitance, Resistance, Diode, Freq. and Temp
- Data Hold and Relative functions



9310

POWRCLAMP 9325

True RMS AC/DC Clamp-on Meter
w/Temp, Cap, Freq and Backlit display

- Measure AC/DC current to 1000A
- Auto Ranging DMM measurements include: AC/DC Voltage, Capacitance, Resistance, Diode, Freq. and Temp
- Perfect for electrical and alarm professionals



9325

Handheld Meter

High Performance Test Equipment



SMIFF-IT B



Coming Soon!

9602

Non-contact AC Voltage Detector
with built in flashlight

- Detect from 30 to 600 Volts AC
- Variable speed
- Light flashes & beeper chirps when AC voltage is present
- Pen sized design with overmolded case

SMIFF-IT 2

Non-contact AC Voltage Detector
with Adjustable Sensitivity

- Quickly identify if wires are energized
- Detect from 5 to 600 Volts AC
- Pocket sized for convenience
- Light and Tone vary with proximity to voltage



9601

PLUG BUG 2

GFCI Receptacle Tester



9610

- Detect common wiring problems
- Push button GFCI test
- Easy to follow graphic explains how to read test results

LINE BUG 4

Phone / LAN Jack tester

- 4 Tri-color LEDs indicate Current, Polarity, & Ringing / AC Voltage on each line
- Check up to 4 lines at once
- Test phone lines for intermittence
- Compact design - fits in shirt pocket



9615

FOR MORE INFORMATION GO TO TRIPLETT.COM



SATALIGN 3



Coming Soon!

3275

Digital Satellite Signal Strength Meter with Tone

- Position dish for peak performance
- Turns a 2 Person Job into a 1 Person Job!
- Great for RV's

Handheld Meter

PAIRMASTER

LAN Cable Test Set

- Test & map 2 Cat5 or Cat6 Cables with included remotes
- Test for: Crossed, Short, Open, Split, Reversed, Double split, Transposed and Cross Talk (NEXT).



3240

High Performance Test Equipment

PAIRMASTER KIT

LAN Cable Test Set w/ 16 remote identifiers and carrying Case

- Test & map up to 16 cat5 or Cat6 Cables with included remotes and accessories
- Test for: Crossed, Short, Open, Split, Reversed, Double split, Transposed and Cross Talk (NEXT).
- Map a complete LAN system quickly



3241

WIREMASTER RJ-45

LAN Cable Test Set

- Verifies point-to-point wiring of RJ-45 patch cables
- 8 LEDs identify the destination of each conductor in cable
- Checks for continuity in straight-through wiring



3251



WIREMASTER XR-2



3254

LAN and telephone Cable Tester with Tone Generator

- Verifies point-to-point wiring of twisted pair LAN cables, telephone cables, and other types of cables that use RJ-45 & RJ-11 connectors
- Generates tone for the Hound 3 to trace
- Save time and money by checking wires quickly

WIREMASTER HDMI2

HDMI Cable Tester

- Test installed HDMI cables with detachable remote
- Test HDMI cables including v1.4
- Manual mode allows for individual conductor testing



3256

WIREMASTER XR-5



3260

5 Cable Test Set

- Test 5 wire types: RJ-11, RJ-45, BNC, Firewire and USB.
- See if wiring is broken, crossed, or shorted with a simple one button test.
- Test installed cables with detachable remote

TDR

Digital Cable Length Meter & Tone Generator

- Easily find distance to fault from one end
- Generate tone in wiring for ease of tracing
- Test all types of communication cables
- 39 standard cable presets or manual selection



3271

WIREMASTER COAX



8-Way Coaxial Cable Mapper

- Reduce troubleshooting time
- Map 8 different coax circuits with included remotes
- A must for CCTV Security and Surveillance systems

3274

CHEK-A-CELL

Sealed Lead Acid Battery Tester

- Load test 6 and 12 volt sealed lead acid batteries
- Works with batteries from 1 to 10 Amp Hours
- Measures within 0.01 volts
- Test batteries in Alarms, UPS's, Emergency lighting and more!



3276

WIREMASTER MAPPER

8-Way Wire & Cable Mapping Kit



- Quickly map all types of cables using 39 remotes and adapters.
- Includes 8 of each: BNC, F, RJ-11/RJ-45 and Alligator clip, remotes and carrying case

3281

FOX JR. & HOUND JR.

Compact Wire and Cable Tracing Kit

- Quickly find security, thermostat and telephone wiring
- Trace low voltage wiring
- Adjustable warble tone
- RJ-11/RJ-45 and Alligator Clip connections



3375



HOTWIRE FOX & HOUND



3388

Live Wire Circuit Tracing Kit

- Identify, locate and trace powered wires from 1V to 220V
- Trace wires up to 1000 feet in length
- Locate wires up to 3 feet away in open air
- Includes modular leads & hard-sided case

FOX 2 & HOUND 3 KIT

Deluxe Wire & Cable Tracing Kit

- Identify, locate, and trace wires inside walls with TrueTrace technology
- Selectable warble or pulse tone
- Visual and audible continuity test
- Designed for Electricians or DIYers



3399


BREAKER SNIFF-IT

Circuit Breaker Locator

- Locate and identify breakers without removing power
- Safely, identify and label breaker locations within any electrical panel



9650

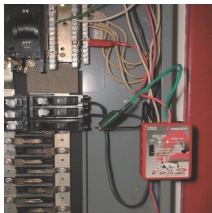



3018

MODEL 310

Analog Hand Sized VOM

- VOM w/18 Ranges and Functions
- Also Available: 3022—310C
- Analog VOM w/18 Ranges and a polarity reversing switch for DC ranges

MODEL 630

Classic VOM - 25 Ranges

- Fuse and diode overload protection
- 6" mirrored scale reduces parallax
- Decibel scale for audio
- AC/DC volts, resistance and DCmA



3030

MODEL 8455

Telco Kick Tester

3 Types Available:

- 3072 - 8455 with test leads & case
- 3073 - 8455 no leads
- 3121 - 8455 with two 72" spike / pin test leads with case



3073

MODEL 60

Ruggedized VOM - 28 Ranges

- 3 fuse design for a high level of protection
- 6" mirrored scale reduces parallax error
- Confidence test to check batteries, fuses, leads, and meter accuracy
- High impact ruggedized case



3145

FOR MORE INFORMATION GO TO TRIPLETT.COM



2010

MODEL 2000

Railroad Test Set

- Measure AC/DC voltage & current, resistance, code parameters, and relay contact on time

Also Available:

- 2011 - 2001: w/100Hz and 250Hz cab filters
- 2012 - 2002: w/100Hz and 200Hz cab filters
- 2013 - 2003: w/60HZ and 250Hz cab filters

Scan, to check out our Facebook page for all the latest news, giveaways, and new product announcements!





INDEX

Product Name	Page #	Product Name	Page #
9007	12	Mini AutoLoader	5
9045	12	MirroBright	10
1101-B	12	Model 310	19
2030-C	12	Model 60	19
BugLite	10	Model 630	19
CablCut	7	Model 8455	19
Camera Extensions	11	ModuLead	2
CamView PTZ	2	PairMaster	15
CamView W35	2	PairMaster Kit	15
CamView W35v	2	Plug Bug 2	14
Chek-A-Cell	17	PowrClamp 9200	13
ClikGrip	6	PowrClamp 9310	13
ClipLite	9	PowrClamp 9325	13
CobraCam 2	10	PowrJaw	6
CobraCam USB 2	10	PowrPress	7
CrossJaw	8	PowrStrip	7
Electrical Testing Kit	4	Professional AutoLoader	5
EnviroMeter	13	ProTemp 12	8
FireFly	3	Railroad Testers	20
FlexSnake	11	Replacement Cameras	11
Fox 2 and Hound 3 Kit	18	Satalign 3	15
Fox Jr. & Hound Jr.	17	Security Bit Kit	5
FUEZR	9	Sniff-It 2	14
GrabLite	9	Sniff-It B	14
HotWire Fox & Hound	18	SoniChek MC	9
Industrial Bit Kit	5	SupraStrip	7
LAN Testing Kit	3	TDR	16
LaserTape 160	8	WireMaster Coax	17
Line Bug 4	14	WireMaster HDMI 2	16
LongLockers	8	WireMaster Mapper	17
Low Voltage Testing Kit	3	WireMaster RJ-45	15
Maintenance Testing Kit	3	WireMaster XR-2	16
		WireMaster XR-5	16



TRIPLETT
Test Equipment & Tools

NOTES

FOR MORE INFORMATION GO TO TRIPLETT.COM



TRIPLETT
Test Equipment & Tools

NOTES

FOR MORE INFORMATION GO TO [TRIPLETT.COM](https://www.triplett.com)



TRIPLETT

Test Equipment & Tools

***100+ Years of Innovation and Commitment
to the Professional!***



***Visit us at Triplett.com
Call us at 800-triplett***

Triplett Test Equipment and Tools

850 Perimeter Rd

Manchester, NH USA

PN: 84-899

Find Us On

