

- Cable Ties
- Cable Ties with Fasteners
- Cable Tie Tools
- Clamps and Clips
- Mounts
- Heavy Duty Mounts
- Wiring Duct
 - Solid Wall
 - Slotted Wall
 - High Density Slotted Wall
- Covers
- Accessories
- Wiring Protection
- Labels, Printers and Software
- Pre - Terminated Networking
- Copper Network Solutions
- Fiber Network Solutions
- Jacks and Wall Plates
- Residential Solutions
- Racks - Cable Management
- Surface Raceway Systems

SLHD3X2G4

High Density Slotted Duct 3" X 2" Non-Adhesive, PVC, Gray, 120' / carton

Article Number: 184 - 32001
 Part Number: SLHD3X2G4
 Type: SLHD3X2
 Material: PVC




- [Find a Distributor](#)
- [Order Samples](#)
- [Get Technical Drawings](#)

1. Base Data

Part No.	SLHD3X2G4
Type	SLHD3X2
Color	Gray
Features	High density slotted wall duct comes with narrow fingers, equaling a 2-to-1 finger ratio compared to standard slotted wiring duct. Narrow fingers reduce fanning of the wires to the terminal blocks. Compact designs and components are more easily accommodated with the high density duct's 2-to-1 finger ratio. High density duct also incorporates the double scored design, similar to the standard slotted wall duct. With sizes 2" high and above, high density duct features a double restriction on each finger of the duct. The double restriction helps retain wires in the bottom portion of the duct for easier installation. Mounting holes are uniform in size to the solid and slotted wall duct, but are offered every 2 inches to accommodate compact designs and installations.

2. Product Dimensions

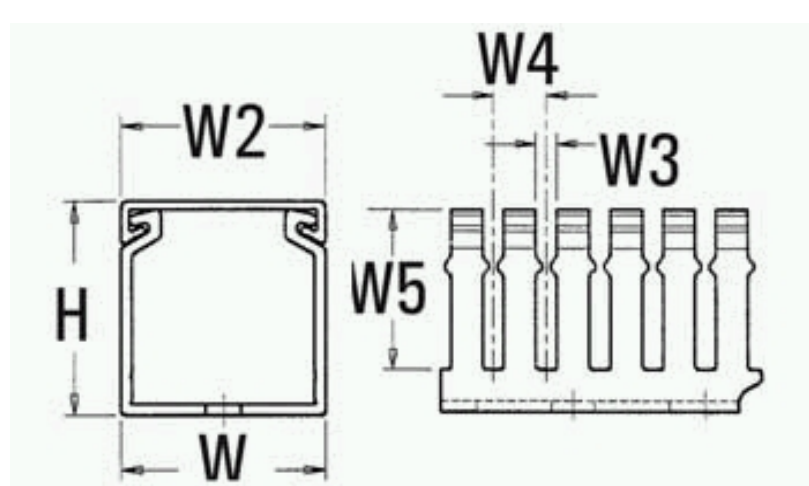

Length (L)	6 ft / 1.83 m
Width (W)	3.03 " / 77.0
Width (W2)	3.00 " / 76.2 mm
Width (W3)	4.1 mm
Width (W4)	.40 " / 10.2 mm
Width (W5)	1.62 " / 41.1 mm
Width (W6)	1.00 " / 25.4 mm
Height (H)	2.06 " / 52.3 mm
Mounting Hole Centers	2.00 " / 50.80 mm

4. Material and Specifications

Material	Polyvinylchloride (PVC)
Material Shortcut	PVC
Certification	CSA / UL
CSA Certified	Yes
Flammability	self -extinguishing
Material Specification	RoHS
Operating Temperature	+122 Â°F (+50 Â°C)

Logistic and Packaging

Packaging Type	carton
Pkg. Qty.	120 ft / 36.6 m
Carton Qty.	120
UPC	08930611412

Miscellaneous

UL Recognized (US and Canada)	Yes
Width (W3)	.16 "

- [Find a Distributor](#)
- [Get Product Samples](#)
- [Get Technical Drawings](#)

Customers Who Bought This Item Also Bought

- 

Wiring Duct Cover Width 3.00" PVC, Gray, 120' / Pkg. Qty.
 Part No: **TC3G4**
 Article No: 181 - 93008
- 

Cable Tie, 18lb, 8.0", Max. Bun. Dia. 2.17" PA66, Natural, 1000/PK
 Part No: **T18L9M4**
 Article No: 111 - 02026
- 

High Density Slotted Duct 2" X 2" Non-Adhesive, PVC, Gray, 120' / carton
 Part No: **SLHD2X2G4**
 Article No: 184 - 22005
- 

Cable Tie Mount 4 Way Mount w/Rubber Adhesive .75"X.75" - PA66, BK, T18 & T30 Cable Ties, 1000/pk
 Part No: **MB3A0M4**
 Article No: 151 - 28713
- 

Wiring Duct Cover Width 1.00" PVC, Gray, 120' / Pkg. Qty.
 Part No: **TC1G4**
 Article No: 181 - 91004

This product was found in [Wiring Duct](#) > [High Density Slotted Wall](#)