CABLES

CABLE ASSEMBLY FOR 5mm & 10mm LED LIGHTS

CNX 440 STANDARD ASSEMBLIES (5mm)

CMC 441 (STANDARD)
CMS 442 (WATER TIGHT)
Display Panel
Lock washer
5mm LED
Socket (2 leads)

CMC 441 (STANDARD)
CMS 442 (WATER TIGHT)
Display Panel
Lock washer
5mm LED
Socket (3 leads)

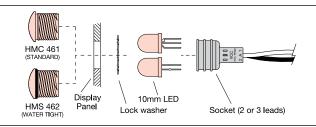|	
LED 5mm bi-lead - trim lead length .250″ ± .01″ (5.58mm) Panel Thickness - .032″ to .125″, Panel Hole: .312″ (8.0mm) Recommended LEDs - 5mm bi-lead, 5mm tri-lead (tri-color) and 5mm six-lead (RGB)	LED 5mm tri-lead - leads custom formed by VCC Panel Thickness - .032″ to .125″ Panel Hole: .312″ (8.0mm)

CNX 460 STANDARD ASSEMBLIES (10mm)

HMC 461 (STANDARD)
HMS 462 (WATER TIGHT)
Display Panel
Lock washer
10mm LED
Socket (2 or 3 leads)

HMC 461 (STANDARD)
HMS 462 (WATER TIGHT)
Display Panel
Lock washer
Hi-Flux LED
Socket (4 leads)

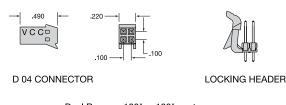|	
LED 10mm bi-lead - trim lead length .300″ ± .01″ (8.13mm) Panel Thickness - .032″ to .187″, Panel Hole: .562″ (14.0mm) Recommended LEDs - 10mm bi-lead, 10mm tri-lead (bi-color), 10mm six lead (RGB) and Hi-Flux four-lead ultra bright.	LED Hi-Flux lead length: Install as is. Panel thickness - .032″ to .187″ Panel Hole: .562″ (14.0mm).

HEADER CONNECTORS AND HEADERS

.100
.200
.490
E 02 CONNECTOR
LOCKING HEADER
Single Row on .100" centers

.490
.220
.100
.100
V C C
D 04 CONNECTOR
LOCKING HEADER
Dual Row on .100" x .100" centers

ORDERING CODES

CNX 440   E02   4   1   12

CONNECTOR STYLE	TERMINATION	WIRE SIZE	WIRE COLOR	WIRE LENGTH
CNX 440 for 5mm LED CNX 460 for 10mm LED See above for avaliable lens options (Sold Separately)	X = STRIPPED END E = SINGLE ROW D = DUAL ROW 02 = 2 Wires 03 = 3 Wires 04 = 4 Wires	STANDARD 4 24 AWG	1 - WHT - BLK 2 - RED - BLK 6 - WHT - BLK - RED 0 - WHT - BLK - RED - GRN	04 4 INCHES 06 6 INCHES 08 8 INCHES 12 12 INCHES 18 18 INCHES 24 24 INCHES

ADDITIONAL OPTIONS AVAILABLE