

Log on



velleman® Inc.

[Log on as distributor](#)

Search product

Search

Product

## Navigation

- ▶ [Main page](#)
- ▶ [Products](#)
- ▶ [Sales outlets](#)
- ▶ [Support](#)
- ▶ [Publications](#)
- ▶ [Jobs](#)
- ▶ [About us](#)

## News

**K8055, K8055N, VM110, VM110N Android Application**

Android application for K8055, K8055N, VM110 & VM110NUSB...

Posted on 09-20-11

[Read more...](#)


[PRODUCT OVERVIEW](#) ▶ [ELECTRONIC COMPONENTS](#) ▶ [LEDS](#) ▶ [FLEXIBLE LED LIGHT STRIPS](#) ▶ [FLEXIBELE LEDMODULES - LDB1-SERIE - MONOCHROOM](#)

## FLEX LED STRIP MODULE - RED - 18 LEDs - 11 13/16" - 12VDC

LDB1-HS3018AR

Support

 [User manual](#)  
[Support](#)



Application: backlighting of diffused glass in illuminated advertising  
- integration of LED light into transparent or diffused glass for emergency signs  
- border marker  
- background illumination  
- escape route markers  
- stair markers

## Features

- optional connection set: LDB1-HS3018/SP
- ROHS compliant

## Specifications

- color: red
- LED quantity: 18 pcs
- power consumption: 2.16W
- power supply: 12VDC
- current per LED: 18mA ± 2mA
- min. cut length: 3 LEDs
- life span: ± 70 000h
- dimensions: 5/8" x 12 1/8"

## Packaging information



Type of packaging:

Plastic Bag




Bar code (EAN-13):

5410329370770

*All registered trademarks and trade names are properties of their respective owners and are used only for the clarification of the compatibility of our products with the products of the different manufacturers. Due to constant product improvements the actual product appearance might differ from the shown images. Product images are for illustrative purposes only.*

[forum.velleman.eu](http://forum.velleman.eu)

## Advertisements

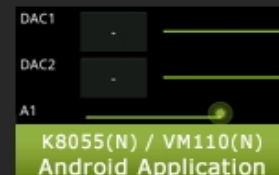

[Click here for  
BBB Business Review](#)