

[Log on](#)**velleman**® Inc.[Log on as distributor](#)

Search product

## Navigation

- ▶ [Main page](#)
- ▶ [Products](#)
- ▶ [Sales outlets](#)
- ▶ [Support](#)
- ▶ [Publications](#)
- ▶ [Jobs](#)
- ▶ [About us](#)

## News

**K8055, K8055N, VM110, VM110N Android Application**

Android application for K8055, K8055N, VM110 & VM110NU5B...

Posted on 09-20-11

[Read more...](#)

[PRODUCT OVERVIEW](#) ▶ [ELECTRONIC COMPONENTS](#) ▶ [TRANSFORMERS, COILS & MOTORS](#) ▶ [MOTORS](#) [DC MOTORS](#)

**6VDC MOTOR 340mA 14400RPM**

MOT2N

Support

[Infosheet](#)  
[Support](#)

## Specifications

- voltage:
  - operating range: 2.5-6V
  - nominal: 6V
- no load:
  - speed: 14500rpm
  - current: 0.21A
- at max. efficiency:
  - speed: 12530rpm
  - current: 1.34A
  - torque: 46.2gcm
  - output: 5.94W
  - eff.: 74.1%
- stall torque: 4.72oz-in
- dimensions (in):
  - A: 0.40
  - B: 0.46
  - C: 1.20
  - D: Ø0.94
  - E: 1.77
  - F: Ø0.08
  - G: Ø0.24
  - H: 0.55
  - I: Ø0.09
  - J: Ø0.94
  - K:

## Packaging information

**Type of packaging:**

Bulk

**Bar code (EAN-13):**

5410329401238

**Bar code (UPC):**

816353010456


*All registered trademarks and trade names are properties of their respective owners and are used only for the clarification of the compatibility of our products with the products of the different manufacturers. Due to constant product improvements the actual product appearance might differ from the shown images. Product images are for illustrative purposes only.*

[forum.velleman.eu](http://forum.velleman.eu)

## Advertisements



[Click here for  
BBB Business Review](#)

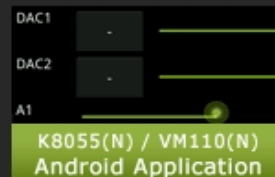

**K8055(N) / VM110(N)  
Android Application**