

[Log on](#)[Log on as distributor](#)

Search product

Navigation

- ▶ [Main page](#)
- ▶ [Products](#)
- ▶ [Where to buy](#)
- ▶ [Support](#)
- ▶ [Publications](#)
- ▶ [Jobs](#)
- ▶ [About us](#)

News

Subscribe to our newsletter

Subscribe to our newsletter to stay updated with what's...

Posted on 06-11-13

[Read more...](#)**Summer Kit contest**

Enter to win Velleman's cool Kits of summer contest.

Posted on 06-06-13

[Read more...](#)**K8055, K8055N, VM110, VM110N iPhone Application**

iPhone application for K8055, K8055N (kit) or VM110,...

Posted on 02-11-13

[Read more...](#)**K8055, K8055N, VM110, VM110N Android Application**

Android application for K8055, K8055N, VM110 & VM110USB...

Posted on 09-20-11

[Read more...](#)velleman[®] Inc.

[PRODUCT OVERVIEW](#) ▶ [ELECTRONIC COMPONENTS](#) ▶ [TRANSFORMERS, COILS & MOTOR MOTORS](#) ▶ [DC MOTORS](#)

3VDC MOTOR 350mA 13800RPM

MOT1N

Support

[Infosheet](#)
[Support](#)

Specifications


- voltage:
 - operating range: 1.5-3V
 - nominal: 3V
- no load:
 - speed: 14200rpm
 - current: 0.3A
- at max. efficiency:
 - speed: 11780rpm
 - current: 1.33A
 - torque: 15.7gcm
 - output: 2.37W
 - eff.: 59.5%
- stall torque: 1.60oz-in
- dimensions (in):
 - A: 0.26
 - B: 0.45
 - C: 0.93
 - D: Ø0.94
 - E: 1.50
 - F: Ø0.08
 - G: Ø0.24
 - H: 0.75
 - I: 0.45
 - J: Ø0.09
 - K: Ø0.94

All registered trademarks and trade names are properties of their respective owners and are used only for the clarification of the compatibility of our products with the products of the different manufacturers. Due to constant product improvements the actual product appearance might differ from the shown images. Product images are for illustrative purposes only.

[REACH communicating information according to article 33 WEEE](#)

forum.velleman.eu

Advertisements

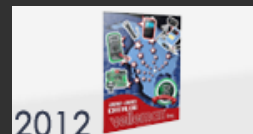

USA CATALOG



CLICK HERE FOR
BBB BUSINESS REVIEW

velleman[®] Inc.

SUBSCRIBE TO OUR
NEWSLETTER



VM201

Download appl



K8055(N) / VM110(N)

ANDROID APPLICATION

© 2013
All rights reserved
[Sitemap](#) | [Disclaimer](#) | [RSS-Feeds](#)