


Item no.: 286-344
 Product description: SWITCHING RELAY MODULE RELAY WITH 1 BREAK CONTACT AND 3 MAKE CONTACTS(3a1r)

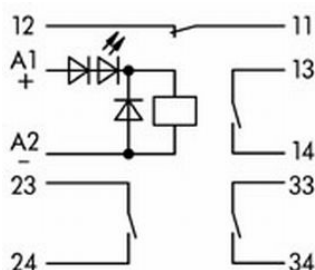

Produkt kann von Bild abweichen / product may differ

Packing unit 1 piece

RoHS compliant

Product group	6 (Electronics)
Coil voltage DC	24 V
Contact material	AuAg10 over AgNi 15
max. switching voltage	AC/DC 250 V
max. make current	20 A
max. break current	5 A
max. continuous current	5 A
max. switching power (resistive) VA	1000 VA
max. switching power (resistive) W	100 W
Pull-in power	50 mW
Operating power	205 mW
Pull-in time (typ)	9 ms
Drop-out time (typ)	5 ms
Bounce time typ	2 ms
Dielectric strength contact-coil (AC, 1 min)	1.5 kV
Nominal voltage acc. to VDE 0110/1.89	Safety data
Mechanical life	2 x 10 ⁸ switching operations
Mechanical life at max. resistive load AC	1 x 10 ⁵ switching operations
Ambient operating temperature	-25 °C ... +40 °C

Current consumption at UN (20 °C)	8.5 mA
Weight	36.66 g
Color	gray

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected