


Item no.: 231-108/026-000  
 Product description: FEMALE PLUG; 8 POLE; PIN SPACING 5 MM / 0.197 IN;  
 WITH CODIG FINGERS; WITH INTEGRATED FIXING  
 FLANGES; CAGE CLAMP®CONNECTION

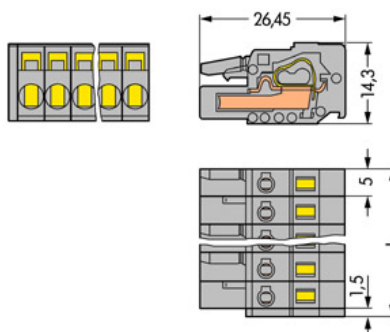

Packing unit 50 pieces

|                                       |                        |
|---------------------------------------|------------------------|
| Product group                         | 3 (Multi Conn. System) |
| Pin spacing from                      | 5 mm                   |
| Pin spacing from                      | 0,197 in               |
| pole count                            | 8                      |
| Cross section from [mm <sup>2</sup> ] | 0,08 mm <sup>2</sup>   |
| Cross section to [mm <sup>2</sup> ]   | 2,5 mm <sup>2</sup>    |
| Cross section from [AWG]              | 28 AWG                 |
| Cross section to [AWG]                | 12 AWG                 |
| Connection method                     | CAGE CLAMP®CONNECTION  |
| Measured voltage EN                   | 250 V                  |
| Measured shock voltage                | 4 kV                   |
| Pollution degree                      | 3                      |
| Current intensity EN                  | 16 A                   |
| Weight                                | 14,48 g                |
| Color                                 | grey                   |
| No. of connection Points              | 8                      |
| No. of potentials                     | 8                      |
| Height                                | 14,3 mm                |
| Height                                | 0,563 in               |
| Width                                 | 41,5 mm                |
| Width                                 | 1,634 in               |
| Depth                                 | 26,45 mm               |



|                   |          |
|-------------------|----------|
| Depth             | 1,041 in |
| Strip length from | 8 mm     |
| Strip length to   | 9 mm     |
| Strip length      | 0,33 in  |



| Item number     | Admission office | Approval no.    | Voltage [V] | Current [A] | Cross section [ mm <sup>2</sup> ] |
|-----------------|------------------|-----------------|-------------|-------------|-----------------------------------|
| 231-108/026-000 | ABS              | 04-HG469925-PDA | 400         | 16          | 5,0                               |
| 231-108/026-000 | BV               | 11915/A0        | 400         | 16          | 2,5                               |
| 231-108/026-000 | CCA              | 5764            | 250         | 16          | 0,08-2,5                          |
| 231-108/026-000 | CSA              | 154112-1466354  | 300         | 15          | 22-12                             |
| 231-108/026-000 | DEMKO            | 88126           | 250         | 16          | 2,5                               |
| 231-108/026-000 | GL               | 17296-00HH      | 400         | 16          | 5,0                               |
| 231-108/026-000 | KEMA             | 2083746.02      | 250         | 16          | 0,08-2,5                          |
| 231-108/026-000 | KR               | HMB05880-EL003  | 250/400     | 12/16       | 2,5                               |
| 231-108/026-000 | LR               | 91/20112(E3)    | 400         | 16          | 5,0                               |
| 231-108/026-000 | RMR              | 11130002        | 400         | 16          | 5,0                               |
| 231-108/026-000 | UR               | E45171          | 600         | 15          | 12                                |
| 231-108/026-000 | UR               | E45172          | 300         | 15          | 22-12                             |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected