


Item no.: 231-110/008-000
 Product description: FEMALE CONNECTOR WITH SNAP-IN MOUNTING FOOT 10 POLE PIN SPACING 5 MM / 0.197 IN WITH CODING FINGERS WITH INTEGRATED FIXING FLANGES SHEET THICKNESS 0.6x1.2 MM 3.5 MMØ WITH MOUNTING FEET 209-137 ON TS 35

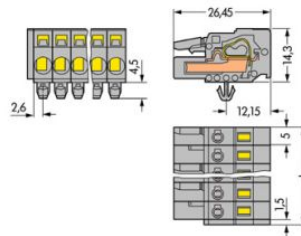

Produkt kann von Bild abweichen / product may differ

Packing unit 50 pieces

RoHS compliant

| | |
|--------------------------|------------------------|
| Product group | 3 (Multi Conn. System) |
| Weight | 18.37 g |
| Color | gray |
| No. of connection Points | 10 |
| No. of potentials | 10 |
| pole count | 10 |
| Height | 14.3 mm |
| Height | 0.563 in |
| Width | 51.5 mm |
| Width | 2.028 in |
| Depth | 26.5 mm |
| Depth | 1.043 in |
| Pin spacing from | 5 mm |
| Pin spacing from | 0.197 in |
| Pollution degree | 2 |
| Measured voltage EN | 320 V |

| | |
|------------------------|-------|
| Measured shock voltage | 4 kV |
| Current intensity EN | 16 A |
| Pollution degree | 2 |
| Measured voltage EN | 630 V |
| Measured shock voltage | 4 kV |
| Current intensity EN | 16 A |



| | |
|----------------------------------|----------------------------|
| Connection method | CAGE CLAMP® CONNECTION |
| Cross section [mm ²] | 0.08 - 2.5 mm ² |
| Wiring method | solid |
| Cross section [mm ²] | 0.08 - 2.5 mm ² |
| Cross section [mm ²] | 0.25 - 1.5 mm ² |
| Cross section [mm ²] | 0.25 - 2.5 mm ² |
| Cross section [AWG] | 28 - 12 AWG |
| Strip length from | 8 mm |
| Strip length to | 9 mm |
| Material group | I |
| xxx-xxx/035-000 | Strain relief plate 50 mm |



| Item no. | Admission office | Approval no. | Voltage [V] | Current [A] | Cross section [mm ²] |
|-----------------|------------------|-------------------|-------------|-------------|-----------------------------------|
| 231-110/008-000 | ABS | 04-HG469925/1-PDA | 400 | 16 | 5,0 |
| 231-110/008-000 | BV | 11915/A0 | 400 | 16 | 2,5 |
| 231-110/008-000 | CCA | 5764 | 250 | 16 | 0,08-2,5 |
| 231-110/008-000 | CSA | 154112-1466354 | 300 | 15 | 22-12 |
| 231-110/008-000 | GL | 17296-00HH | 400 | 16 | 5,0 |
| 231-110/008-000 | KEMA | 2083746.02 | 250 | 16 | 0,08-2,5 |
| 231-110/008-000 | KR | HMB05880-EL003 | 250/400 | 12/16 | 2,5 |
| 231-110/008-000 | LR | 91/20112(E3) | 400 | 16 | 5,0 |
| 231-110/008-000 | RMR | 11130002 | 400 | 16 | 5,0 |
| 231-110/008-000 | UR | E45171 | 600 | 15 | 28-12 |
| 231-110/008-000 | UR | E45172 | 300 | 15 | 22-12 |

Sorting criteria: admission office - approval number

© WAGO Kontakttechnik GmbH & Co. KG

Specifications are subject to changes and errors may be expected